

Features

- External
- 0 mm → 25 mm
- Imperial & Metric
- Battery powered
- Accuracy ± 0.004 mm

RS PRO External Micrometer, 0 mm → 25 mm range

RS Stock No.: 705-1229



RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

Product Description

A high-quality Imperial and Metric Micrometer for external measurements.

- *For measurements up to 25mm/1in*
- *Resettable origin point*
- *Automatic power-off*
- *Lockable spindle*
- *Carbide measuring faces*
- *Ideal for workshop and electronic applications*

General Specifications


Micrometer Type	Digital
Imperial or Metric	Both
Display Type	LCD
Accuracy	±0.004 mm
Resolution	0.001mm
Thumb roller	Yes
Button function	on/off, zero, mm/inch
Resettable Origin Point	Yes

Mechanical Specifications

Internal/External	External
Range	25mm/1in
Jaw Length	32mm
Spindle Diameter	6mm

Approvals

Compliance/Certifications	DIN863/1, DIN40050/IEC529, BS EN 61340-5-1, ANSI/ESD S20.20
---------------------------	---

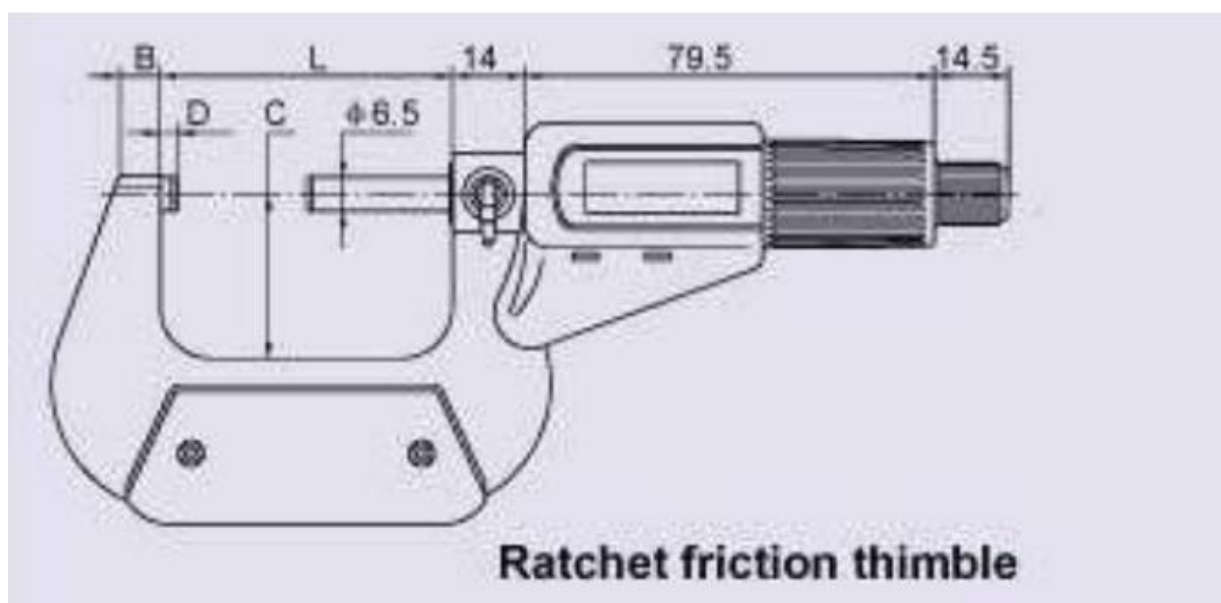

C	L	B	D
24mm	32mm	6mm	3mm