


Product Datasheet

Rechargeable

eneloop AAA

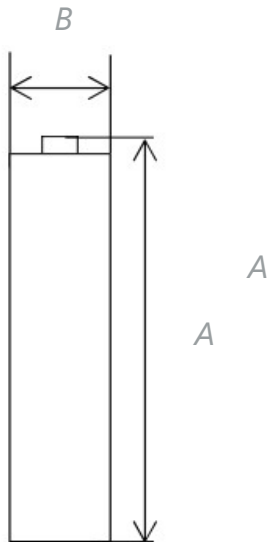


BK-4MCDE

IEC Dimensions (mm)		
Dimension	Maximum	Minimum
A	44,5	
B	10,5	

Name	BK-4MCDE
Size	AAA
Type	NiMH rechargeable
Nominal Voltage	1.2 V
Made in	Japan
Average weight	13 g
Capacity (minimum)	800 mAh
Ambient temp. charge	0°C - 40°C
Ambient temp. discharge	-20°C - 50°C
Internal impedance (after discharge to E.V.=1.0V)	Approx. 40mΩ (at 1000Hz)

Typical characteristics

Charge

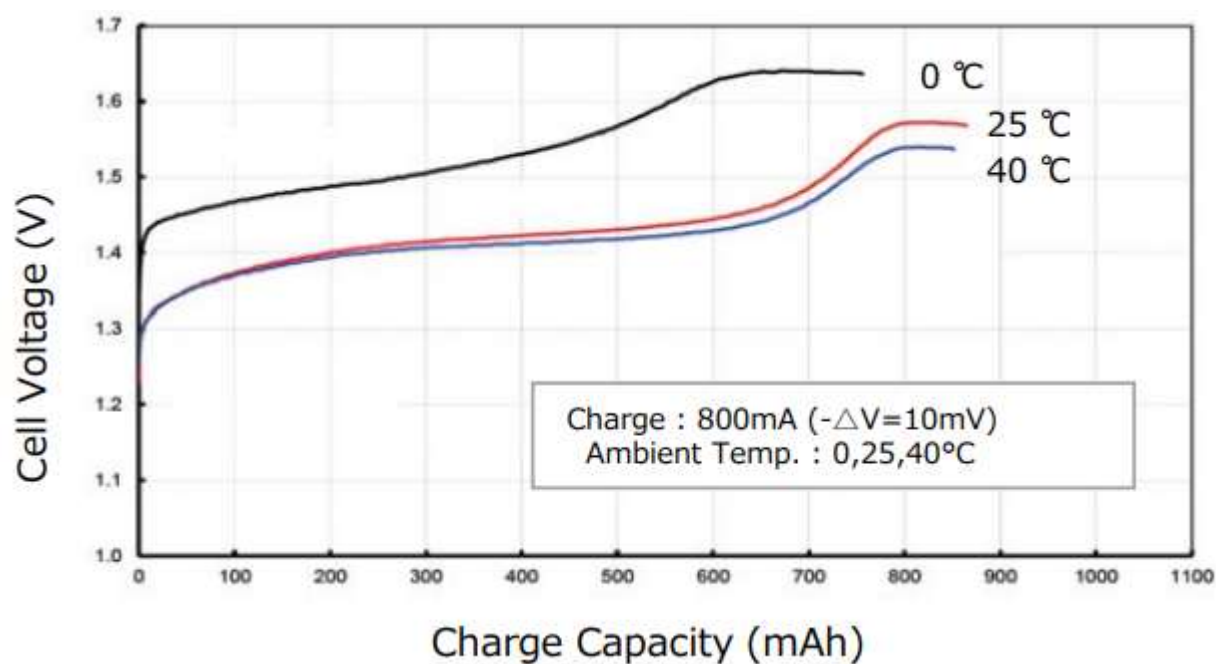

Discharge

