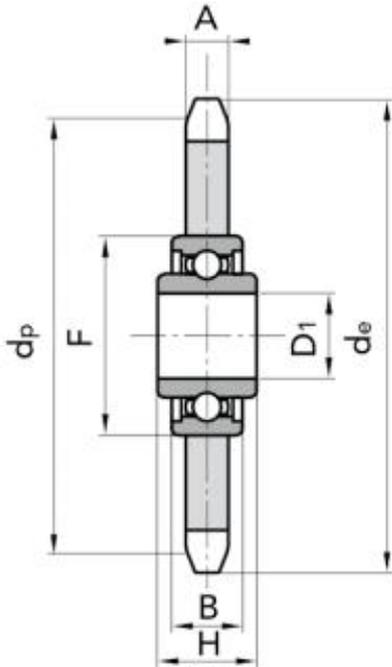


**30019015**

With economic bearing - Idler sprocket

**2D Technical Drawing**

**Dynamic 3D View**

**Technical Specifications**

|                     |              |
|---------------------|--------------|
| Number of teeth (T) | 15           |
| Pitch (P) mm        | 3/4" x 7/16" |
| de (DE) mm          | 99.8         |
| dp (DP) mm          | 91.63        |
| Part number (CODE)  | 30019015     |
| A (A) mm            | 11.1         |
| D1 (D1) mm          | 16           |
| F (F) mm            | 40           |
| B (B) mm            | 12           |
| H (H) mm            | 18.3         |
| Weight (WEIGHT) kg  | 0.47         |
| Material (MAT)      | STEEL C45    |