

Overvoltage protection socket strip 7-fold with switch

Item-No.: 0206x00072301 (1,5 m cord) | 0206x00072303 (3 m cord) | 0206x00072305 (5 m cord)



Robust plastic, grey

Built-in sockets (90° rotated), round

Extra large space in between sockets 64 mm

1,5 m power cord and angle plug (optional with 3 m or 5 m power cord)

Expanded contact protection by using a shutter

End caps with mounting possibility and spare fuse

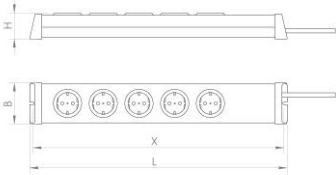
Optical function display and acoustic fault message

EHMANN advantage - the connected devices will remain in operation after release overvoltage protection



Overvoltage protection socket strip 7-fold with switch

Technical data

3.600 W Power	230 V ~ (+/- 10%) / 50 Hz Rated voltage	16 A Rated current
Power Cord: H05VV-F 3G 1,5 mm ² Plug: CEE 7/7 plug Type EF, angled Sockets: earthing contact Type F Switch: 2-pole, illuminated Consumption per switch: < 0,4 W Voltage U _n : 230 V~ Max. continuous operation voltage U _c : 255 V~ Nominal discharge voltage U _{oc} : 5000 V Protection level Up: L-N < 1,0kV - L/N-PE < 1,5kV Rated leakage current I _{max} (8/20): 6,5 kA Fuse: T6,3AH/250 V SPD according to EN 61643-11: Typ3 Consumption overvoltage protection: < 0,1 W Safety class: IP20		  
 (similar illustration)		
Item-No. 0206x00072301 (1,5 m cord) EAN 4012096027041 Item-No. 0206x00072303 (3 m cord) EAN 4012096006671 Item-No. 0206x00072305 (5 m cord) EAN 4012096006688		590 x 74 x 47 mm Dimensions (L x W x H) 582 mm Fixing Dimension