


FEATURES

- **Nylon Material:** Provides strength and flexibility for various applications
- **Non-Releasable Design:** Ensures a secure and permanent hold
- **UV Resistant:** Suitable for outdoor use, resisting degradation from sunlight
- **Length of 200mm:** Accommodates a wide range of bundling needs
- **Maximum Bundle Diameter of 48mm:** Capable of securing larger cable groups
- **Tensile Strength of 34kg:** Offers robust support for heavy-duty applications
- **Width of 4.6mm:** Balances strength and flexibility
- **Fire Behaviour UL 94 V-2:** Meets safety standards for flammability

RS PRO Nylon Cable Tie, 200mm Non-Releasable

RS Stock No: 656-010

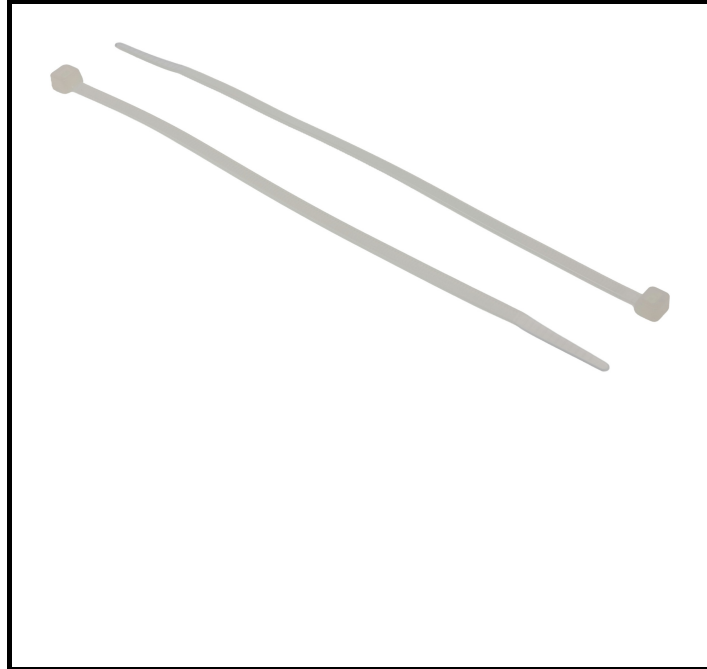

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

RS PRO offers a reliable nylon cable tie designed for secure bundling and organising of cables and wires. With a length of 200mm, this non-releasable cable tie is ideal for applications requiring a permanent hold. Its UV resistance ensures durability in outdoor environments.

General Specifications

Colour	Natural
Product Type	Cable Tie
Sub Type	Non-Releasable
Tensile Strength	34 kg

Protection Category

Fire Behaviour	UL 94 V-2
UV Resistant	Yes

Mechanical Specifications

Length	200 mm
Material	Nylon
Maximum Bundle Diameter	48 mm
Width	4.6 mm

Operation Environment Specifications

Maximum Operating Temperature	85 °C
-------------------------------	-------

Approvals

Standards/Approvals	ABS 15-TA1338482-PDA, cULus E97527, RoHS, UL94V-2
---------------------	---

