


# DX08WR024N Datasheet

Product Name // DX08WR024N, 8mm Diameter, Wire Leads 200mm, Red, 24V, Nickel Plated Brass

 [View Product Page](#)

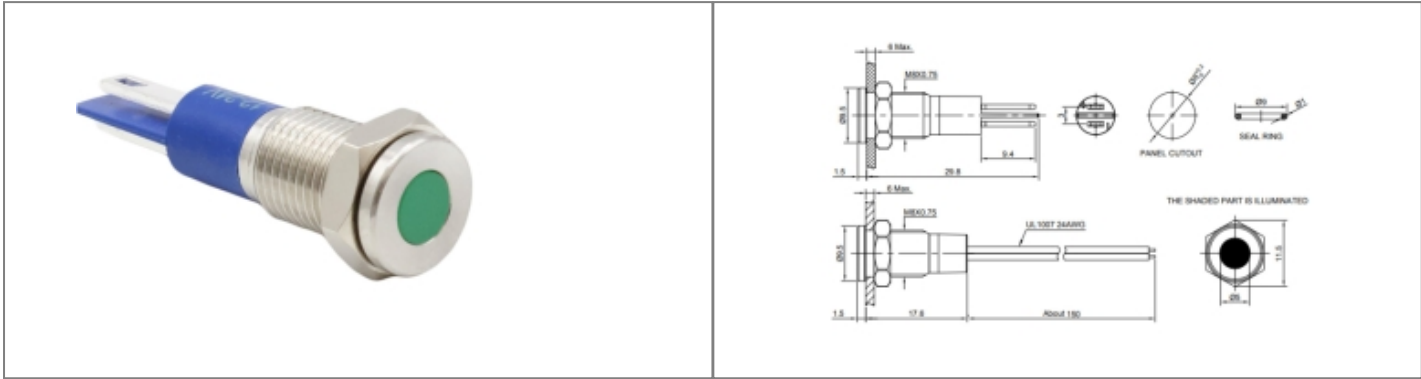

### // Product Description:

- |                                                                                                      |                                                                                                         |
|------------------------------------------------------------------------------------------------------|---------------------------------------------------------------------------------------------------------|
|  DX Range           |  Red                   |
|  8mm Diameter      |  24V                  |
|  Wire Leads 200mm |  Nickel Plated Brass |

### // General Information:

|                                  |                                         |
|----------------------------------|-----------------------------------------|
| Product Display Title:           | 8mm Vandal Resistant Indicator DX Range |
| Product Family:                  | Indicators                              |
| Product Series:                  | 8mm Vandal Resistant Indicator DX Range |
| Bezel Finish:                    | Polished                                |
| Body Colour:                     | Nickel                                  |
| Body Material:                   | Brass                                   |
| Body Material Type:              | Metal                                   |
| Diameter:                        | 8mm                                     |
| Dielectric Withstanding Voltage: | 1500V                                   |
| Function:                        | Vandal Resistant Indicator              |
| Illumination Colour:             | Red                                     |
| Illumination Voltage:            | 24V                                     |
| Indicator Profile:               | Flat-round                              |
| Insulation Resistance:           | ≥100MΩ(500VDC)                          |
| Ip Rating:                       | IP67                                    |
| Material Finish:                 | Polished                                |
| Max Operating Temperature:       | 55°C                                    |
| Min Operating Temperature:       | -25°C                                   |
| Max Panel Thickness:             | 6mm                                     |
| Panel Cut Out:                   | 8mm Diameter Circle                     |
| Rohs Compliant:                  | Yes                                     |
| Thread Size:                     | M8 X 0.75                               |

#### // Product PDF Links

 [6mm & 8mm Vandal Resistant...](#)

#### // Product 3D CAD Model Links

 [DX08WR024N3D CAD Model](#)



Have a question or project enquiry  
you'd like to talk to us about?



[Click Here To Contact Us](#)