



Hot-melt Glue Applicators

Cordless hot-melt glue applicator neo2

Overview Hot-melt Glue Applicators

Information copy

Powerhouse for mobile hot-gluing. Robust cordless hot-melt glue applicator neo2 from STEINEL is an indispensable helper in the workshop, garage and home, cordless gluing with rechargeable Li-Ion battery, ready for gluing in 15 sec.



Details

Powerhouse!


The neo2 cordless hot-melt glue applicator for the workshop, garage, hobby and home. For high-strength, permanent bonding and insulation of virtually all materials – metal, wood, plastics, ceramics and much more besides.

The cordless neo2 cordless hot-melt glue applicator is a DIY tool with professional qualities. Strong, flexible, accurate, neat and ready to start gluing in 15 sec. The new anti-drip system (ATS) means the adhesive is automatically drawn back into the nozzle on releasing the feed button. Preventing glue from being delivered unnecessarily. The adhesive is dry after 10 sec. and reaches final bonding strength in less than 2 min. The rechargeable lithium-ion battery is a strong performer too: providing 30 minutes of continuous use on one battery charge. The battery charges in less than 3 h using the micro-USB charger provided. Temperature is controlled electronically: the heating cartridge only heats the nozzle head, the rest of the tool stays cool. The cordless hot-melt glue applicator switches off automatically when not in use. Product benefits in brief: 275 g, heating-up time of just 15 sec, 30 min rechargeable battery run time during continuous use, 3 h battery recharging time, complete with micro-USB charger.

Let the professionals show you.

[Click here to go to the test report](#) in MFI Modellflug magazine 10/2013.

[Click here to go to the test report](#) in ModellFan magazine 11/2013.

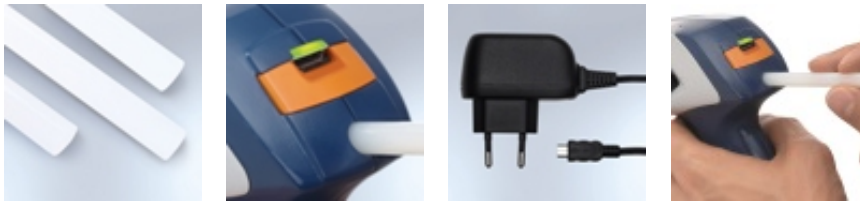

Technical specifications Cordless hot-melt glue applicator neo2

European Article Number (EAN)	4007841334208
Max. glue capacity	8 g/min
Max. stick diameter	7 mm
Max. stick length	150 mm
Warming-up time	0.25 min
Weight of machine	0.446 kg
Dimensions (l x w x h)	157 x 47 x 158 mm
Voltage	3.6 V lithium-ion rechargeable battery
Min. frequency	50 Hz
Max. frequency	60 Hz
Warm-up time	approx. 15 seconds
Melt temperature	170 °C
Delivery rate	3 g /min.
Rechargeable-battery run time	P00257v001
Battery charging time	90% in 3 hours
Weight	275 grams
Model	Folding box
Glue sticks	Ø 7 mm

Application

DIY and repair work.
An indispensable helper in the workshop, garage and home.



Example application 1



Example application 2



Example application 3



Example application 4



Example application 5

