



RCJTZ60-XL-I


Flanged housing unit

Housing units RCJTZ, two-bolt flanged housing units, cast iron, centring spigot, eccentric locking collar, R seals

Schaeffler ID:
0008317350000

X-life

Technical information

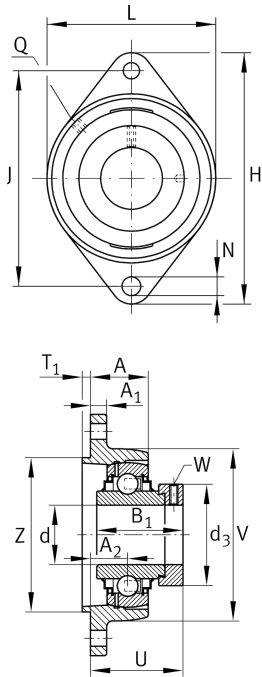

Your current product variant

Material	GG	Grey cast iron
----------	----	----------------

Main Dimensions & Performance Data

d	60 mm	Bore diameter
L	138 mm	Flange width
H	238 mm	Height flange
U	76,9 mm	Total height unit
C _r	52.000 N	Basic dynamic load rating, radial
C _{0r}	36.000 N	Basic static load rating, radial
C _{ur}	1.710 N	Fatigue load limit, radial
≈m	3,9 kg	Weight

Mounting dimensions

J	202 mm	Distance fixing bore
N	18 mm	Fixing bore
T ₁	4 mm	Height spigot
Z	130 mm	Diameter spigot
	h8	Diameter spigot clearance
n	2	Number of screwing holes



Dimensions

A	42 mm	Height housing
A ₁	16 mm	Thickness of flange
A ₂	30 mm	Distance raceway
B ₁	77,9 mm	Locking collar total width
V	138 mm	Shoulder diameter housing
Q	Rp1/8	Connection thread for lubrication
d ₃	84 mm	Outside diameter eccentric locking collar

Additional information

1	Number of housings
GG.CJTZ12-I	Housing
GE60-XL-KRR-B	Bearing designation

Temperature range

T _{min}	-20 °C	Operating temperature min.
T _{max}	100 °C	Operating temperature max.