

SITOR CYLINDRICAL FUSE LINK AR 40 A,
660 V AC/700 V DC



Similar to image

Technical data:

Current / for AC / rated value	A	40
Supply voltage		
• for AC / rated value	V	690
• for DC	V	500
Switching capacity current		
• in accordance with IEC 60947-2 / rated value	kA	200
Design of an identification indicator		others
Ambient temperature	°C	-20 ... +50

Certificates/approvals:

General Product Approval

Declaration of Conformity



[ROSTEST](#)



[Manufacturer](#)


Further information:

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<http://www.siemens.com/lowvoltage/mall>

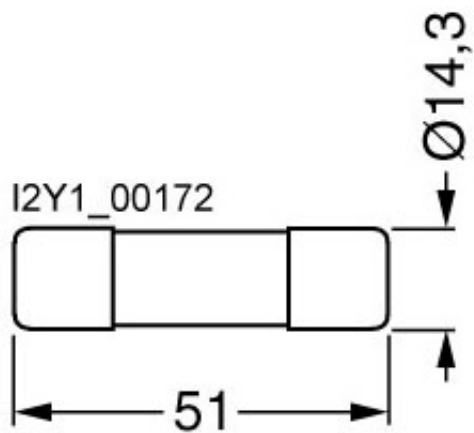

last change:

Mar 10, 2012