


NATR8

Galet de roulement

Yoke type track rollers NATR..., single row needle roller bearings with particularly thick-walled outer ring, needle roller and cage assembly and an inner ring, axial guidance of outer ring is provided by the contact washers, gap seals on both sides

Information technique

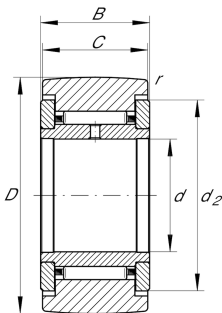

Votre alternative produit actuelle

joint	SPSP	Gap seal on both sides
profile bague extérieure	R500	Diamètre extérieur sphérique (Standard)
dispositif de lubrification	IR	Via inner ring

dimensions principale & données de performance

d	8 mm	Alésage
D	24 mm	Diamètre extérieur
B	15 mm	Largeur, bague intérieure
C _{r w}	5.500 N	Charge dyn. de base, radiale
C _{0r w}	6.700 N	Charge stat. de base, radiale
C _{ur w}	940 N	Limite à la fatigue, radiale
n _{D G}	7.500 1/min	Vitesse pour une lubrification à la graisse
F _{0r per}	6.700 N	Charge radiale statique admissible
F _{r per}	6.700 N	Charge radial dynamique admissible sur bague extérieure
≈m	0,04 kg	Poids

Dimensions

C	14 mm	Largeur, bague extérieure
d ₂	19 mm	Diamètre extérieur rondelle de butée
r _{min}	0,3 mm	Dimension minimum de chanfrein
R	500 mm	Rayon bague extérieure profile externe



Caractéristiques



Effort radial



Lubrification à la graisse



lubrification à l'huile



Ouvert