


KEMET, FLLD4-TH, EMI/RFI Filters, Noise Suppression, 520 VAC, 16 A, 120x115x80mm

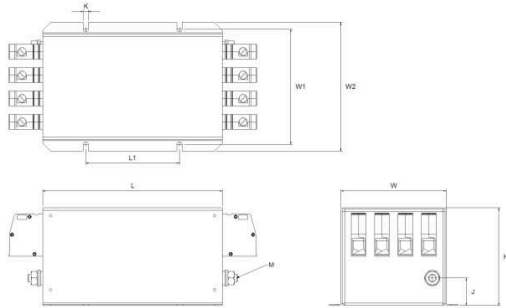

General Information	
Series:	FLLD4-TH
Style:	Chassis Mount
Description:	EMI Filter, Classis Mount, Compact
Features:	Three Phase, High Performance
RoHS:	Yes
Qualifications:	IEC/EN 60939
Lead:	Threaded Studs M6

Dimensions	
L	120mm NOM
W	115mm NOM
H	80mm NOM
L1	80mm NOM
W1	127.5mm NOM
W2	143mm NOM
J	32mm NOM
K	6.5mm NOM
M (Earth)	Threaded Studs M6
Lead	Threaded Studs M6

Specifications	
Voltage AC:	520 VAC, 300 VAC
Rated Frequency:	50-60 Hz
Ripple Current:	16 A (50°C)
Rated Temperature:	50°C
Temperature Range:	-25/+100°C
Climate Category:	25/100/21
Test Voltage DC (P to P):	2250 VDC
Test Voltage DC (P to E):	3000 VDC
Voltage:	2250 VDC (Test P to P), 3000 VDC (Test P to E)
Power Loss:	6 W (25°C 50 Hz)
Leakage Current:	11 mA

Packaging Specifications	
Packaging:	Bulk
Packaging Quantity:	1
Weight:	800 g