
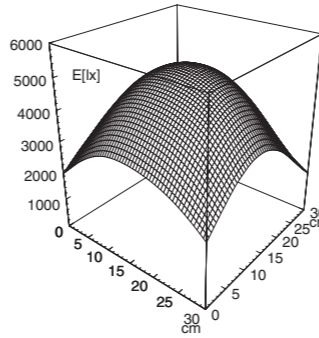
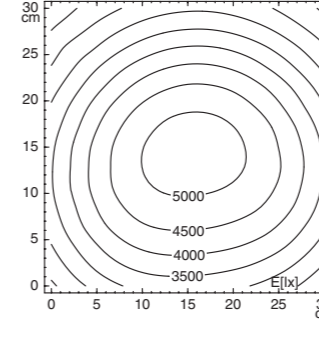
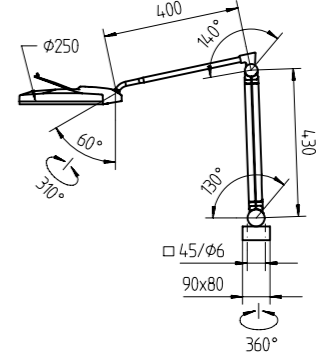

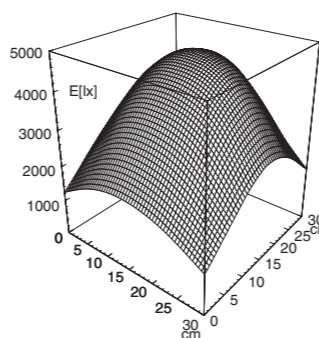
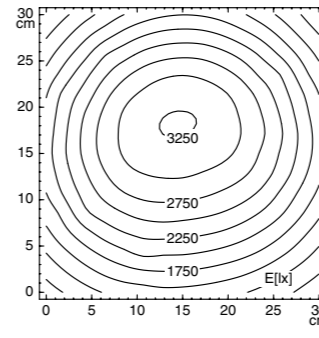
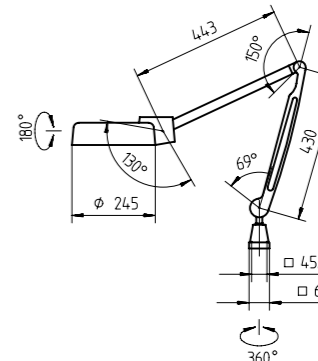


MAGNIFIER LUMINAIRES

MODEL	TECHNICAL DATA	COLOURS	ORDER NUMBERS	LIGHT DISTRIBUTION	TECHNICAL DRAWINGS	ACCESSORIES/ORDER NUMBERS
 <p>LRE 122</p>	<p>LRE 122 connected load: fitted with:</p> <p>100/120/230V ; 50/60Hz 1 x fluorescent lamp T-R16 22 W neutral white electronic ballast approx. 3 m; shock-proof plug</p> <p>work equipment: mains lead: luminaire body: material: tubular sections: material: surface: weight (net): fastening:</p> <p>plastic</p> <p>steel tube painted approx. 2,7 kg screw-down flange, table clamp (accessory), wall bracket (accessory)</p> <p>technology: usage: lamp cover: balance of articulation joints: class of protection: lens; dimensions: lens; diopters:</p> <p>switchable switch polycarbonate; white opal</p> <p>spring I Ø 120 mm 3,5</p>	<p>Luminaire body light grey RAL 7035</p> <p>Tubular section light grey RAL 7035</p>	112 223 000	  <p> E_{min}: 1219 lx E_m: 3590 lx E_{max}: 5253 lx </p> <p>Measurement distance: 15 cm</p>	 <p> Table clamp TK black Span 0 – 45 mm 190 008 019 0 – 65 mm 190 007 019 65 – 135 mm 190 033 019 95 – 165 mm 190 035 019 Wall bracket black 300 213 018 Magnifier (4 diopters) 190 184 019 Magnifier (3,5 diopters) 190 184 029 Magnifier (6 diopters) 190 184 039 Magnifier (4 diop. + bifokal) 190 184 049 </p>	
	<p>LRE 122 As above, but weight (net): lens; diopters:</p> <p>approx. 2,9 kg 4,0</p>	<p>Luminaire body light grey RAL 7035</p> <p>Tubular section light grey RAL 7035</p>	112 223 002			
	<p>LRE 122 As above, but weight (net): lens; diopters:</p> <p>approx. 2,8 kg 6,0</p>	<p>Luminaire body light grey RAL 7035</p> <p>Tubular section light grey RAL 7035</p>	112 223 003			
	<p>LRE 122 As above, but weight (net): lens; diopters: add-on lens:</p> <p>approx. 2,9 kg 4,0 Ø 30 mm / total 12 Diopters</p>	<p>Luminaire body light grey RAL 7035</p> <p>Tubular section light grey RAL 7035</p>	112 223 006			
 <p>RLL 122T</p>	<p>RLL 122T connected load: fitted with:</p> <p>230 V/ 50 Hz 1 x fluorescent lamp T-R29 22 W neutral white conventional ballast approx. 2.9 m; Euro plug</p> <p>work equipment: mains lead: luminaire body: material: weight (net): fastening:</p> <p>plastic</p> <p>approx. 3,1 kg table clamp (accessory), wall bracket (accessory)</p> <p>technology: usage: lamp cover: balance of articulation joints: class of protection: lens; dimensions: lens; diopters:</p> <p>switchable switch polycarbonate; white opal</p> <p>spring II Ø 120 mm 4,0</p>	<p>Luminaire body light grey RAL 7035</p> <p>Tubular section light grey RAL 7035</p>	111 851 000	  <p> E_{min}: 838 lx E_m: 2162 lx E_{max}: 3255 lx </p> <p>Measurement distance: 15 cm</p>	 <p> Table clamp TK black Span 0 – 45 mm 190 008 019 0 – 65 mm 190 007 019 65 – 135 mm 190 033 019 95 – 165 mm 190 035 019 Wall bracket black 300 213 018 Magnifier 190 054 019 </p>	
	<p>RLL 122T As above, but add-on lens:</p> <p>Ø 30 mm / total 12 Diopters</p>	<p>Luminaire body light grey RAL 7035</p> <p>Tubular section light grey RAL 7035</p>	111 851 001			