


Features

- Fits standard rectangular cutout.
- Front or rear mounting through the panel.
- Various hole mounting options.
- No soldering or punch termination. Use standard cable for each connector style.
- Low rear profile.

RS PRO Panel Mount 2 Port MMC Adaptor

RS Stock No.: 0726435, 0726438, 0726436, 0726436B

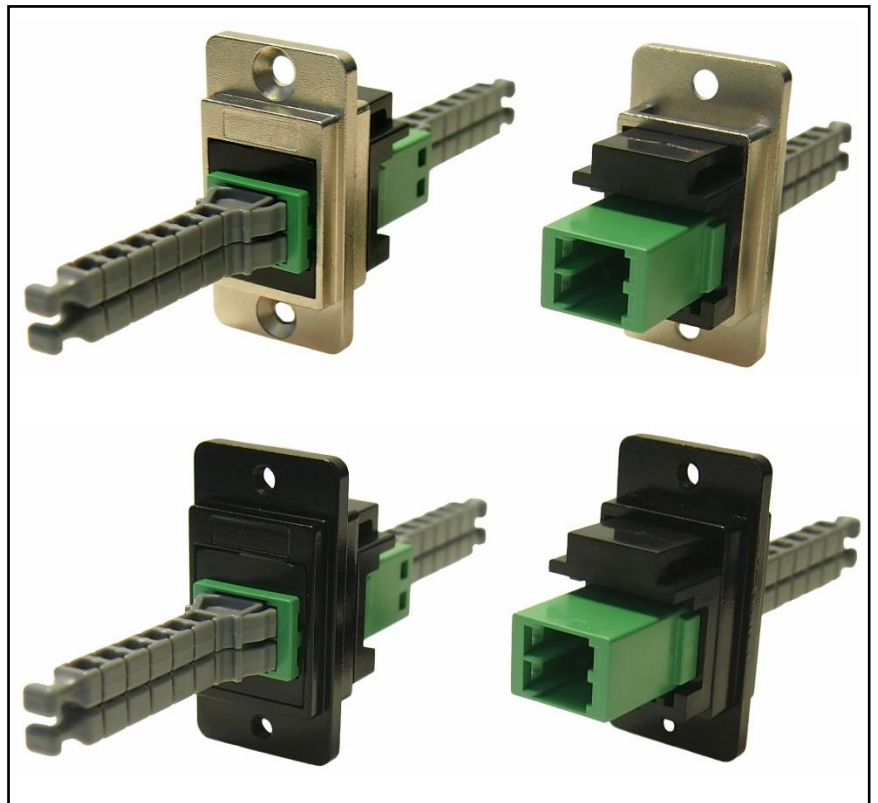

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

MMC is a Very Small Form Factor (VSFF) multi-fibre optical connector designed for termination of multiple single-mode and multimode fibre cables in the AI Data Centre environment. This 2 port MMC Feedthrough Adaptor will accept one or two US CONEC APC polish connectors and is supplied with two single port dust covers on the front and rear (four in total)

General Specifications

Connector Type	MMC Adaptor
Mounting type	Panel mount
Mounting Frame material	Diecast, Nickel or Black plated
Mounting hole	See table below
MMC Body material	PEI UL94-V0 Green
Dust Cap material	PC UL94-V0 Grey
Inner frame	ABS/PC UL94-V0

Mechanical Specifications

Operating Temperature	-30° to +80°C
-----------------------	---------------

Approvals

Standards Met	RoHS
---------------	------

Similar Products

Stock No.	Brand	Product Name	Mounting hole	Mounting Frame Material
0726435	RS PRO	MMC Adaptor	Ø3.2mm Countersunk	Diecast, Nickel plated
0726438	RS PRO	MMC Adaptor	Ø3.2mm Countersunk	Diecast, Black plated
0726436	RS PRO	MMC Adaptor	M3 holes	Diecast, Nickel plated
0726436B	RS PRO	MMC Adaptor	M3 holes	Diecast, Black plated

