


**KEMET Part Number: 100MS26ACMA1STD**  
(A902GP100V260A)

MS/A902, Aluminum Electrolytic, 100 uF, -0/+25%, 260 VAC, -20/+60°C

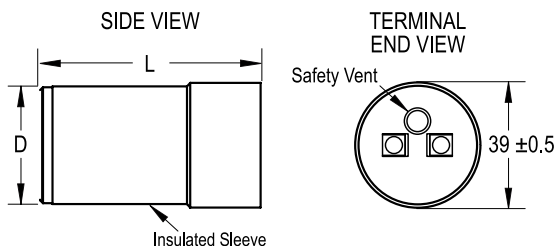

General Information	
Supplier:	KEMET
Series:	MS/A902
Dielectric:	Aluminum Electrolytic
Description:	Motor Start Aluminum Electrolytic
RoHS:	Yes
Lead:	Quick Connect
AEC-Q200:	No
Shelf Life:	156 Weeks

Dimensions	
D	38mm +/-0.5mm
L	116mm MAX

Packaging Specifications	
Packaging:	Bulk, Bag

Specifications	
Capacitance:	100 uF
Capacitance Tolerance:	-0/+25%
Voltage AC:	260 VAC
Temperature Range:	-20/+60°C
Rated Temperature:	60°C
Life:	500 Hrs