


LONG LIFE IN METAL DEMOLITION

PRO

- 1 Combines hard teeth and flexible body through Bi-Metal welding
- 2 Vario tooth design for smooth cutting
- 3 Robust thick blade for good straight cuts

 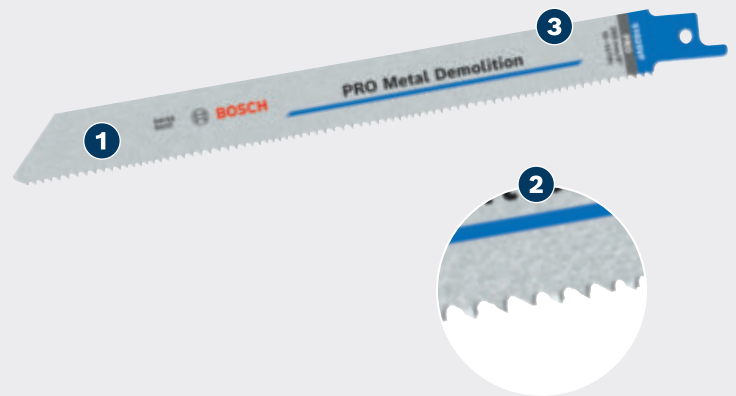


* vs Bosch S1122BF



BOSCH

PRO METAL DEMOLITION S1025VF BLADE

PRO


- ▶ For cutting metal sheets, pipes and profiles efficiently, eg mild steel pipes and interior fittings, metal cladding
- ▶ Highly efficient for metal recyclers: Long Life
- ▶ Lasts up to 3x longer than a Bosch S1122BF Blade
- ▶ Fits all S-shank reciprocating saws



PRODUCT PROPERTIES							ORDERING INFORMATION				
Tooth spacing [mm]	Tooth pitch [TPI]	Dimensions LxWxT [mm]	Blade material abbreviation	Recommended min. material thickness [mm]	Recommended max. material thickness [mm]	Max. cut capacity [mm]	Packaging type	Pack quantity	Minimum order quantity	Barcode	Part number
1.8-2.6	10-14	200 x 19 x 1.25	BIM	2.5	10	150	C1c	5	5	235 570	2 608 656 265


BOSCH