


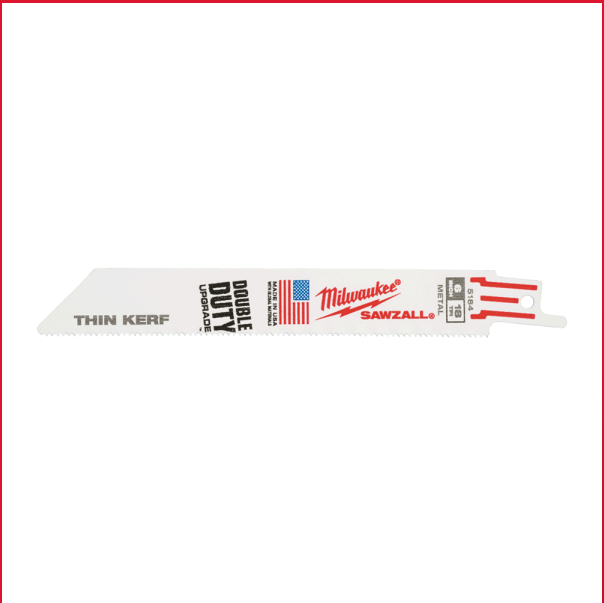

# 150mm x 18 Tpi - 5 pc

## METAL: THIN KERF BLADES

- Improved tooth geometry for best speed and double the lifetime.
- Bi-metal quality cutting teeth with 8% cobalt giving the ultimate in performance and lifetime.
- TOUGH NECK™: Stamped indentations around the reception strengthens the blade at its weakest point.
- Slim 0.90 mm thick blade body optimised for maximum speed and flexibility.



|                                               |                                                                                                                     |
|-----------------------------------------------|---------------------------------------------------------------------------------------------------------------------|
| Article Number                                | 48475184                                                                                                            |
| Blade length (mm)                             | 150                                                                                                                 |
| Materials suited for                          | Thick metal > 4 mm Medium metal 1.5 - 4 mm Thin metal 0.5 - 3 mm Stainless steel Non ferrous metal (Cu/Al) PVC pipe |
| Max. cutting capacity metal pipe              | ø 10 - 100                                                                                                          |
| Max. cutting capacity non ferrous metals [mm] | 1.5 - 8                                                                                                             |
| Max. cutting capacity stainless steel [mm]    | 1.5 - 4                                                                                                             |
| Max. cutting capacity steel (mm)              | 1.5 - 8                                                                                                             |