



Product Compliance


[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JAN 2025 (247) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Reflow solder capable to 260°C


Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>


Compatible Parts

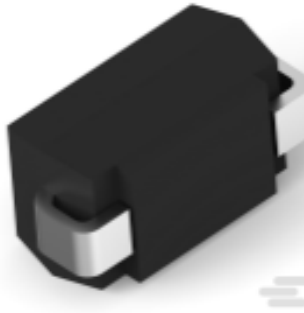


TE Part # 2176322-8
SMV 1W 390K 5%

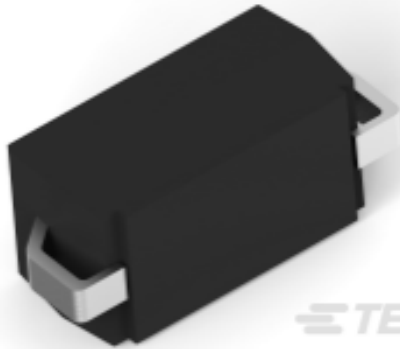


TE Part # 2176324-1
SMV 3W 100K 5%

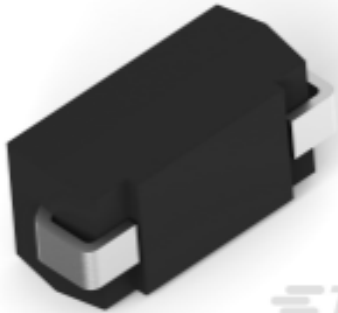


TE Part # 2-2176323-5
SMV 2W 10M 5%

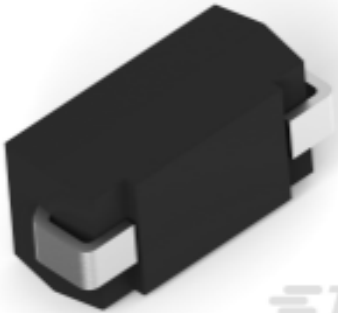

TE Part # 2176323-9
SMV 2W 470K 5%

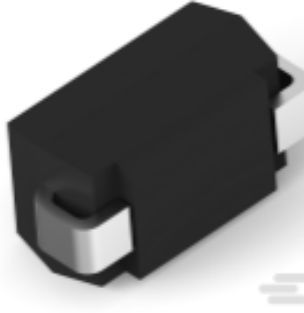

TE Part # 2176322-5
SMV 1W 220K 5%

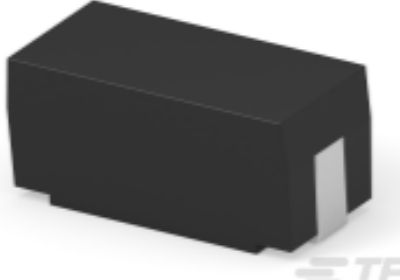

TE Part # 6-2176620-0
SMQF3W 150K 5%


Customers Also Bought




TE Part #1571983-3
GDH02STR04=DIP SWITCH



TE Part #5-2176070-6
3521 2K0 1% 2W

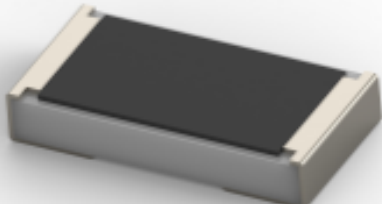


TE Part #CAT-C339-A76B
SMD Power Resistor: 3 Watt, 1% Tol

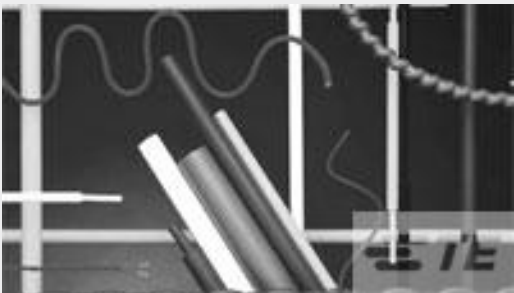

TE Part #5069802018
CGPT-1.6/0.8-0-STK



TE Part #3-1825059-0
ADF06STTR04=DIP S,FLUSH,SMT-GW

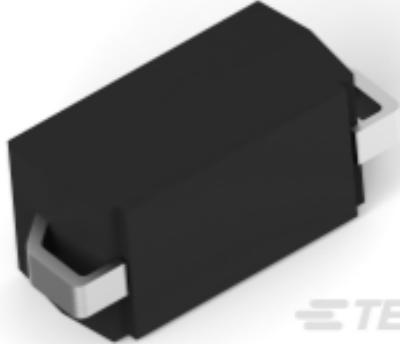

TE Part #2176324-4
SMV 3W 180K 5%



TE Part #7-1879233-3
SMW5 100R 5%



TE Part #2176347-1
CRGCQ 2010 10R 1%



TE Part #1-1462039-8
IM06DGR=IM RELAY 140mW 12V

Documents



Product Drawings

SMV 3W 150K 5%

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_2176324-3_BA.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_2176324-3_BA.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_2176324-3_BA.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

Metal glaze High Voltage SMD Resistor Type SMV series

English