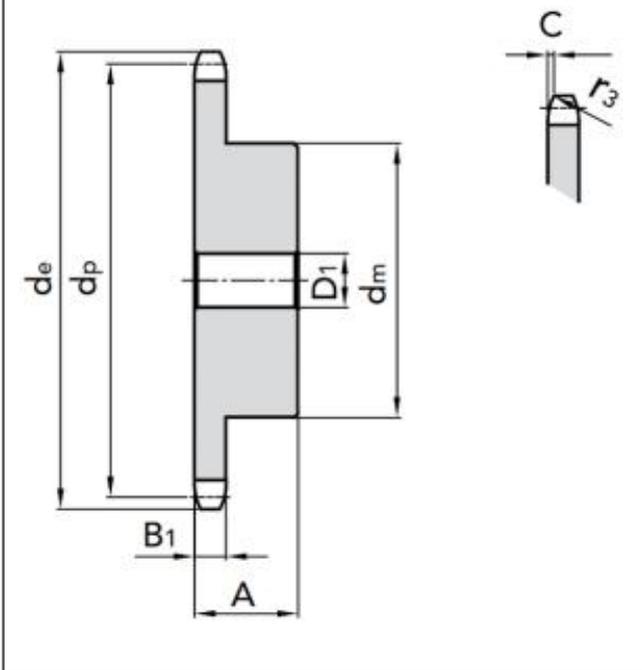
 


**10112015**

1/2in x 5/16in - Chain sprockets ISO

**2D Technical Drawing**

**Dynamic 3D View**

**Technical Specifications**

Number of teeth (T)	15
de (DE) mm	65.57
dp (DP) mm	61.09
Part number (CODE)	10112015
dm (DM) mm	45
D1 (D1) mm	10
A (A) mm	28
Tooth radius r3 (R3) mm	13
Radius width C (C) mm	1.3
Sprockets tooth width B1 (B1) mm	7.2
Weight (WEIGHT) kg	0.38
Material (MAT)	STEEL C 45