


## Data sheet

Commercial Art.No.: 57.503.8855.0

Initiator terminal WK 2,5-3 D/U /V0

Initiator terminal with Screw connection for mounting on TS 35 / TS 32, nominal cross section: 2.5 mm<sup>2</sup>, Width: 6 mm, Color: grey

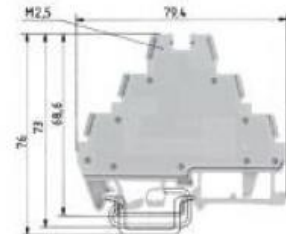

Commercial Art.No.	57.503.8855.0
EAN	4015573511743
Order Unit	50

Certificates / Approvals



## Technical data

### General

Nominal cross section	2.5 mm <sup>2</sup>
Colour	Grey
Number of levels	3
Number of clamp positions per level	2
Width/grid dimension	6 mm
Insulating housing	PA666
Inflammability class of insulation material acc. with UL94	V0
Mounting method	DIN rail (top hat rail)/G-rail
Terminal blocks for electrical installations	No

### Technical data

Rated current	24 A
Rated voltage	400 V
Rated impulse voltage	6 kV
Pollution degree	3
Closing plate required	No
Type of insulation material	Thermoplastic
Length	79.4 mm

### Connection Data

Connection type 1	Screw connection
Connection type 2	Screw connection
Minimum cross section solid	0.5 mm <sup>2</sup>
Maximum cross section solid	4 mm <sup>2</sup>
Minimum cross section fine stranded	0.5 mm <sup>2</sup>
Maximum cross section fine stranded	2.5 mm <sup>2</sup>
Wire strip length	7 mm
Torque conductor mounting	0.4 Nm

**Technical Data UL/CSA**

Cross section UL	22-12 AWG
Voltage UL	300 V
Current factory wiring	25 A
Current field wiring	20 A
Cross section CSA	22-12 AWG
Voltage CSA	300 V
Current CSA	25 A

**Note**

Display	None
Power supply function	No

**Classification**

ECLASS 8.1	27141128
ETIM 7.0	EC000900
ETIM 6.0	EC000900
ETIM 5.0	EC000900
ETIM 4.0	EC000900
ETIM 3.0	EC000900

**Accessories**

<b>Commercial Art.No.:</b>	<b>Article-type description:</b>	<b>Description:</b>
----------------------------	----------------------------------	---------------------

**Fits with**

<b>Commercial Art.No.:</b>	<b>Article-type description:</b>	<b>Description:</b>
----------------------------	----------------------------------	---------------------