



fitted with

work equipment
 connected load
 power consumption
 luminous flux
 luminous efficacy
 light distribution
 Beam Angle
 light colour
 color rendering index (CRI)
 system of protection
 class of protection
 technology
 usage
 luminaire body
 lamp cover
 tubular sections
 balance of articulation joints
 weight (net)
 mains lead

LED

Energy efficiency category A+
 electronic plug-in transformer
 100-240 V; 50/60 Hz
 approx. 7 W
 approx. 460 lm
 approx. 66 lm/W
 direct, wide-angled beam
 30

daylight white, approx. 5700 K
 > 72

IP 20 (65)

II

switchable

switch

aluminium, anodised, black

glass screen

flexible metal tube, Jet black

friction

approx. 1.6 kg

approx. 2.7 m; mains plug

BS 1363

CEE 7/XVI

NEMA 1-15P

fastening

screw-down flange, magnetic base (accessory), table clamp (accessory), wall bracket (accessory)

accessory

Interchangeable mains plug

special features

Flood with 40° angle of radiation



BS 1363



CEE 7/XVI




NEMA 1-15P

illuminance

Distance: 50 cm

Em: 3000 lx
 Emax: 5958 lx
 Emin: 721 lx

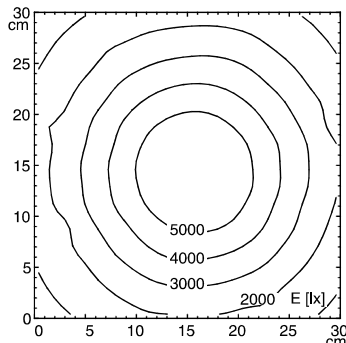

luminous intensity

