




ENGLISH

Datasheet

RS Pro Vinyl-Insulated Double Crimp Male Disconnectors

Stock Number: 125-1953

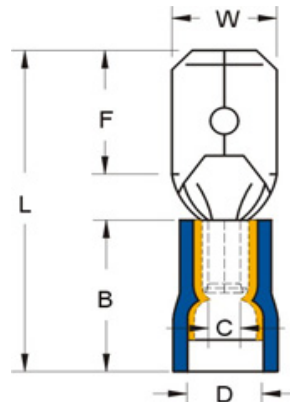

WIRE RANGE A.W.G. / mm ²	ITEM NO.	NEMA TAB	DIMENSION inch(mm)						Q'TY BOX
			W	F	L	B	D	T	
16-14 A.W.G.	MDD2-250	.032X.250	0.25	0.303	0.858	0.413	0.185	0.016	1000
1.5-2.5 mm ²		(0.8X6.35)	6.35	7.7	21.8	10.5	4.7	0.4	

Maximum Electric Current:

A.W.G.	16	14
AMP.	10	15

Maximum Electrical Rating: 105°C 600 V Max

Insulation Material: Vinyl

Insulation Colour: 16 – 14 AWG (Red)

Terminal Material: Brass

Double Crimp: With copper sleeve on barrel

Terminal Barrel ID: 16 – 14 AWG C = 2.3 mm