

Long-reach C-clamp lock-grip pliers





Standards:

ASME B107.500

Description:

- Special forged-steel jaws for secure clamping of angle sections and deep channels
- Pressed-steel body.
- "R" models have hinged shoes at their tips.
- Hand-screw adjustment.
- Finish: chrome.

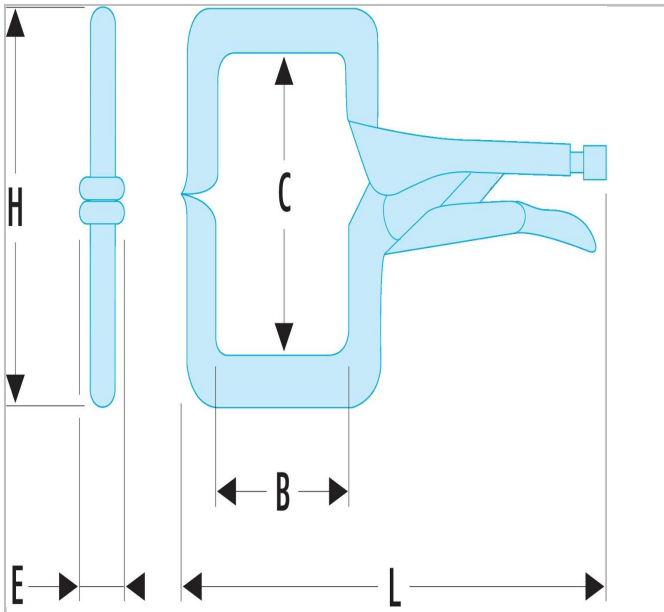

	Length L [mm]	Head Height C [mm]	Head Width B [mm]	Height H [mm]	A Maxi [mm]	Weight [g]	Thickness E [mm]
514.45R	175.0	60.0	45.0	90.0	45.0	270.0	19.0
514A.240	460.0	100.0	240.0	165.0	230.0	1400.0	20.0
514A.240R	460.0	100.0	240.0	165.0	230.0	1500.0	32.0
514A.400	630.0	100.0	400.0	165.0	370.0	1700.0	20.0
514A.65	300.0	100.0	65.0	150.0	70.0	905.0	12.0