


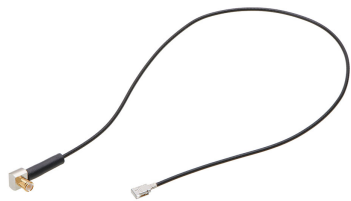

**Part Number :** [732306150](#)  
**Product Description :** MCX Right-Angle Plug-to-I-PEX MHF I LK Plug, 1.37mm Cable Diameter, 305.00mm Cable Length, 50 Ohms  
**Series Number :** 73230  
**Status :** Active  
**Product Category :** RF Cable Assemblies



## Documents & Resources

**Drawings**  
[732306150\\_sd.pdf](#)

## Product Environment Compliance

### Compliance

GADSL/IMDS	Not Relevant
China RoHS	Not Reviewed per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Not Reviewed per IEC 61249-2-21
REACH SVHC	Not Reviewed per D(2024)6225-DC (07 Nov 2024)
EU RoHS	Compliant with Exemption 6(c) per EU 2015/863

### Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

### Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

### EU RoHS Certificate of Compliance

## Part Details

### General

Status	Active
Category	RF Cable Assemblies
Series	73230
Description	MCX Right-Angle Plug-to-I-PEX MHF I LK Plug, 1.37mm Cable Diameter, 305.00mm Cable Length, 50 Ohms
Assembly Configuration	Dual Ended Connectors
Connector to Connector	MCX-to-I-PEX MHF
Product Name	I-PEX MHF,MCX
Type	RF Cable Assembly
UPC	196823189159

### Electrical

Impedance	50Ω
-----------	-----

### Physical

Cable Length	305.00mm
Gender	Plug/Plug
Material - Metal	Brass
Material - Plating Mating	Gold
Net Weight	2.500/g
Packaging Type	Bag
Single Ended	No
Wire/Cable Type	1.37mm, Coaxial