
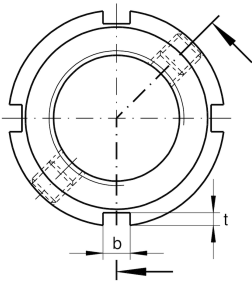


ZM120

Precision locknut

Precision locknut ZM, accessory ZM..

Technical information

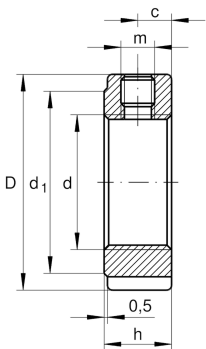

Main Dimensions & Performance Data

d	M120X2	Thread
D	155 mm	Outside diameter
h	24 mm	Height
M _A	20 Nm	Mounting torque set screw
F _{aB}	580,000 N	Breaking load, axial
M _L	600 Nm	Breakawag
M _{AL}	450 Nm	Mounting torque reference
M _M	68.4 kg*cm2	Mass moment of inertia

≈m 1.371 kg Weight

Dimensions

d ₁	138 mm	Plant diameter outside
t	5 mm	Hight retaining slot
b	12 mm	Width retaining slot
c	12 mm	Distance bore
m	M10	Threaded - threaded pin