

FEATURES

- Red spade connector
- Wire size range of 0.5 mm² to 1.5 mm², 22 AWG to 16 AWG
- Tab size of 0.8 mm x 6.3 mm
- Length of 21.5 mm
- Shrouded
- Crimp termination method
- Nylon insulation
- Brass contacts

RS PRO Red Insulated Spade Connector, 6.3 x 0.8mm Tab Size, 0.5mm² to 1.5mm²

RS Stock No.: 267-4350



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

This RS PRO spade connector allows you to quickly connect and disconnect wires from circuits without the need for soldering. Its most often used to connect single wires to relays or components. Designed for crimp termination, once one end has been crimped with a pair of pliers or crimpers, a stripped wire can be easily slotted into the opposite end of the connector. The flaring of the insulation makes insertion even easier. Nylon insulation makes your circuits safer and more reliable by preventing the sort of unintended metal contacts that can lead to short-circuiting.

General Specifications

Insulation	Insulated
Orientation	Straight
Shrouded/Unshrouded	Shrouded
Insulation Material	Nylon
Termination Method	Crimp
Connector Type	Tab
Contact Material	Brass
Colour	Red
Applications	Used in domestic appliances, like dishwashers and washing machines


Mechanical Specifications

Minimum Wire Size	0.5mm ²
Maximum Wire Size	1.5mm ²
Tab Size	6.3mm x 0.8mm
Minimum Wire Size (AWG)	16AWG
Maximum Wire Size (AWG)	22AWG
Tab Thickness	0.8mm
Tab Width	6.3mm
Overall Length	21.5mm

Approvals

Compliance/Certifications

EN61340

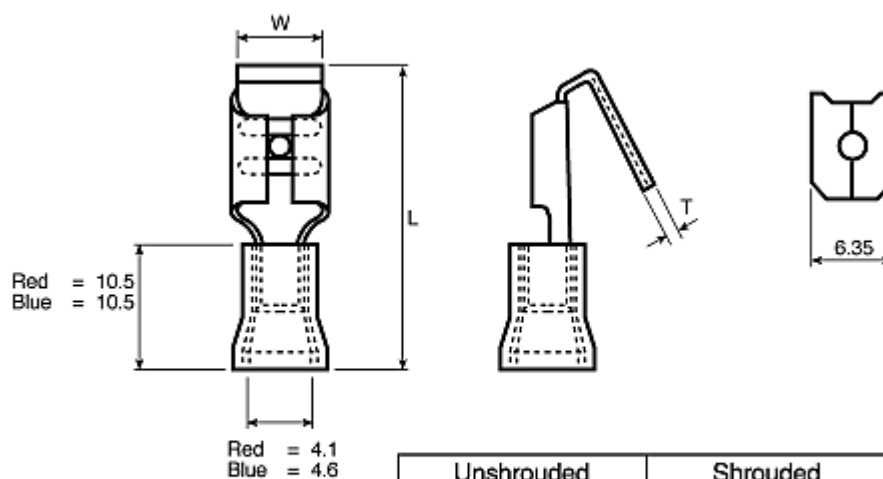

	Unshrouded			Shrouded		
	W	L	T	W	L	T
Red	6.6	22.7	0.8	9.4	21.5	0.8
Blue	6.6	22.7	0.8	9.4	21.5	0.8