
4000 K

LEDriving T4W – Premium | LED – Interior lighting



Areas of application

- Interior lighting

Product benefits

- 5 year guarantee
- Perfect light distribution thanks to modern diffusor material
- Two different light colors for a variety of customization options
- Maintenance-free thanks to long lifetime of up to 5,000 h
- Up to 80 % less energy consumption (compared to standard lamps)
- Easy plug & play replacement

Product features

- LED retrofit lamps for various applications in vehicle interiors
- LEDT4W available with color temperature: 4,000 K, 6,000 K
- LEDT4W available with light color: Warm White, Cool White
- Shockproof and vibration-proof

Product datasheet

Technical data


Electrical data

Power input	1 W
Nominal wattage	4.00 W
Nominal voltage	12 V
Test voltage	13.2 V

Photometrical data

Color temperature	4000 K
Luminous flux	50 lm
Luminous flux tolerance	±10 %

Dimensions & weight

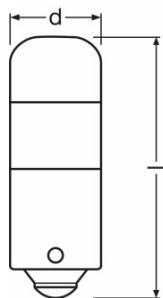

Length	27.4 mm
Diameter	9.0 mm
Product weight	2.70 g

Lifespan

Lifespan B3	500 h
Lifespan Tc	1000 h

Additional product data

Base (standard designation)	BA9s
-----------------------------	------

Certificates & standards

ECE category	-
--------------	---

Country specific categorizations

Product datasheet

Order reference	3850WW-02B 1W 1
------------------------	-----------------

Product datasheet

Logistical Data

Product code	Product description	Packaging unit (Pieces/Unit)	Dimensions (length x width x height)	Volume	Gross weight
4008321657893	4000 K	Blister 2	73 mm x 30 mm x 57 mm	0.12 dm ³	10.00 g
4008321657909	4000 K	Shipping carton box 10	104 mm x 106 mm x 78 mm	0.86 dm ³	94.00 g
4008321667199	4000 K	Shipping carton box 420	- x - x -		

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

References / Links

Guarantee terms are available at

▶ www.osram.com/am-guarantee

Legal advice

Not ECE conform

Only approved for off-road use when used in an exterior application. Illegal use on public roads leads to cancellation of vehicle operating licence and loss of insurance cover.

Disclaimer

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.