

Datasheet

Stock No: 121-7825, 121-7826, 121-7827

RS Pro Sockets for Miniature Power Relay




Specifications:

- Comes with metal retaining clip
- Suitable for 121-7804, 121-7806, 121-7807, 121-7808, 121-7809, 121-7810, 121-7811, 121-7812, 121-7813, 121-7814, 121-7815, 121-7816, 121-7817, 121-7818, 121-7819, 121-7820, 121-7821, 121-7822, 121-7823, 121-7824

RS Stock No	121-7825	121-7826	121-7827
Characteristics			
Nominal Load	Current	16A	
	Voltage	300V	
Dielectric Strength	Between Coil and Contact	4000 V/S	
	Between Contacts	2500 V/S	
Max. Tightening Torque	1.2Nm		
Wire Size	20-14 AWG / 0.5-2.5mm ²		
Ambient Temperature	-40~+85°C		
Unit Weight	46g	62g	78g
Accessories	Metal Retaining Clip		
Certification			

Dimensions

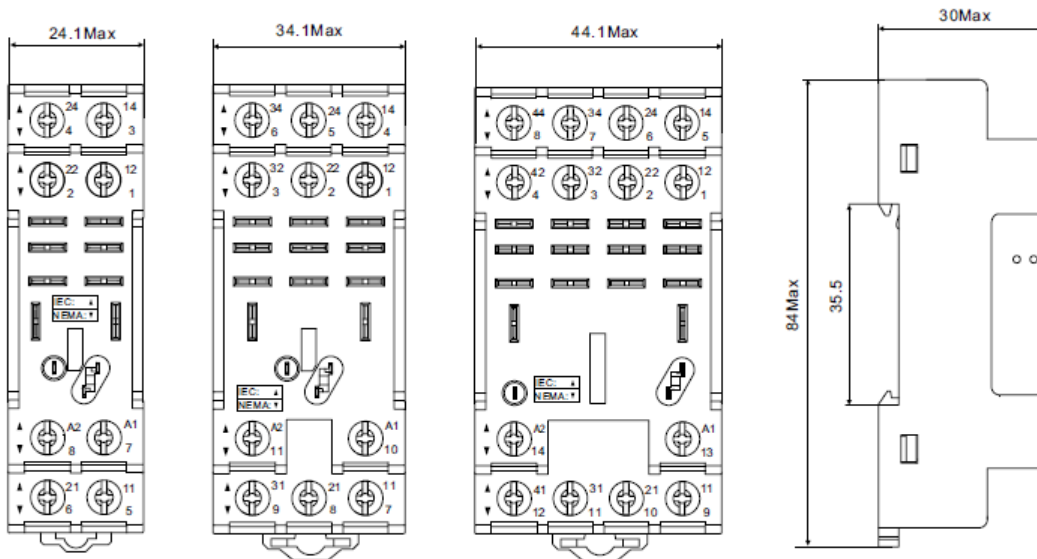

Connection Diagram

