



Brand of NTN Group

Technical data

UCF217
Bearing units




Grey cast housing, radial insert ball bearing with socket set screws, seal with slinger

KIT CONTENT

UC217G2, F217

VISUAL (S)

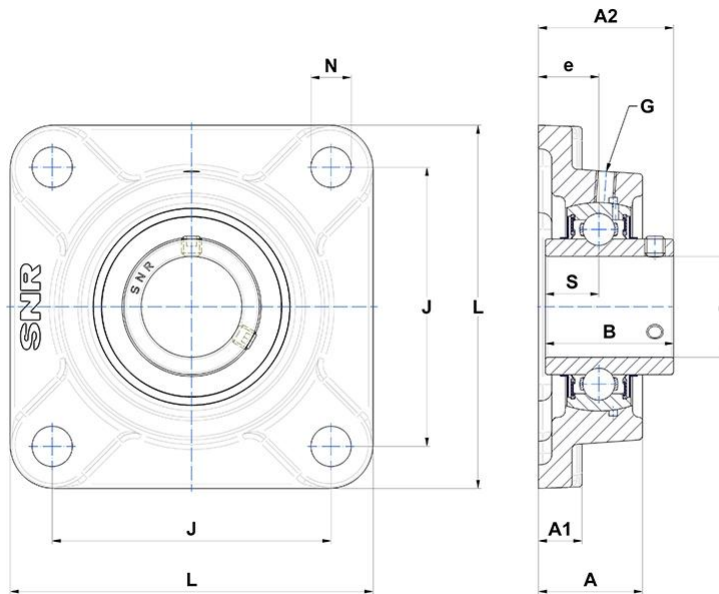

PRODUCT DEFINITION

Brand	SNR
A - Housing height	63 mm
A1 - Housing foot height / flange height	24 mm
A2 - Total height from mounting surface	87,6 mm
B - Width of Inner Ring	85,7 mm
d - Shaft diameter	85 mm



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT DEFINITION

e - Distance mounting surface to bearing center	36 mm
G - Grease fitting	M10x1
J - Mounting holes distance	175 mm
L - Housing width / diameter	220 mm
N - Mounting hole dimension	23 mm
S - Distance front side/bearing centre	34,1 mm

PRODUCT PERFORMANCE

C - Dynamic load rating	83200000 mN
C0 - Static load rating	63800000 mN
Operating temperature min.	253,15 °K
Operating temperature max.	373,15 °K

OTHER FEATURES

Mass	8,66 kg
Recommended tightening torque for set screw	33 N-m

