



T-handle wrench, extra long

97-12

97-...

SAM Outillage

10 rue Camille de RochetaillÃ©e
42000 Saint-Etienne - France

RCS Saint-Etienne B 338 002 231 | SAS au capital de 8 189 583 â‚¬

<https://www.sam-outillage.com/>

Photos and texts not contractually binding. Do not litter. Document generated on 2025-07-18 08:52:35





DESCRIPTION

T-handle wrench, extra long

Made of forged chrome-vanadium steel and treated 48 HRC (160 kg/mm²). Universal joint articulation, making it possible to manoeuvre difficult-to-access nuts. Very long body, 6-flat socket, sliding pin. Tightening possible up to 90°. Female square on the end of the body. Presentation: polished chrome-plate.

STANDARDS / DIRECTIVES

NF ISO 691, NF ISO 2236, DIN 475-1

SAM Outillage

10 rue Camille de RochetaillÃ©e
42000 Saint-Etienne - France


RCS Saint-Etienne B 338 002 231 | SAS au capital de 8 189 583 â‚¬

<https://www.sam-outillage.com/>

Photos and texts not contractually binding. Do not litter. Document generated on 2025-07-18 08:52:35



SPECIFIC DATA

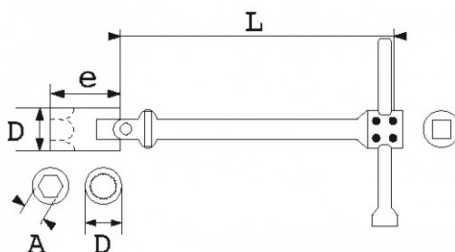

Designation	SHAFT WRENCH STD 6 PTS 3/8" 12MM
Sales reference	97-12
L (mm)	455
Weight (g)	370
e (mm)	35
D (mm)	17.6
Number of points	6
A (mm)	12
drive square	3/8"
Guarantee	O

Guarantee applied

O | SAM TOOL guarantee.

Guarantee without time limit on the tools used under normal conditions.

[>> Find out more](#)

SAM Outillage

10 rue Camille de RochetaillÃ©e
42000 Saint-Etienne - France

RCS Saint-Etienne B 338 002 231 | SAS au capital de 8 189 583 Å

<https://www.sam-outillage.com/>

Photos and texts not contractually binding. Do not litter. Document generated on 2025-07-18 08:52:35

