


Part Number: 1860235X

Type	Size	Rating	Description
LED	T10	24Vac/dc	10mm BA9s/13 LED

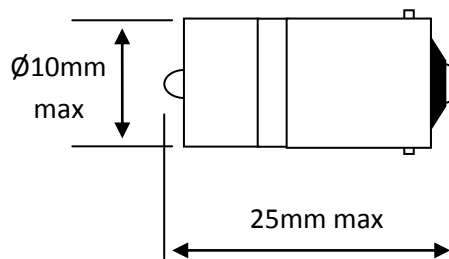

Part no.	Colour	Current(mA)	Intensity(mcd)
18602350	Red	15	900
18602351	Green	15	1900
18602352	Yellow	15	600
18602357	Blue	15	750
1860235W3A	White clear	13	3500
1860235W3DA	White diffuse	13	2300

Notes:

- 1 Electrical & optical data are measured at an ambient temperature of 25°C
- 2 Lamp base in accordance with BS EN 60061-1:BA9s
- 3 Storage temperature -25 °C to +80°C
- 4 Application temperature -20 °C to +60°C
- 5 Due to component tolerances, colour temperature variations may be observed
- 6 The plastic(polycarbonate) has limited chemical resistance
- 7 RoHS & REACH SVHC compliant