


KEMET Part Number: SSHB10H-05212
(UALSB105212000)

KEMET, SSHB10H, AC Line Filters, Dual Mode, 0.0212 H

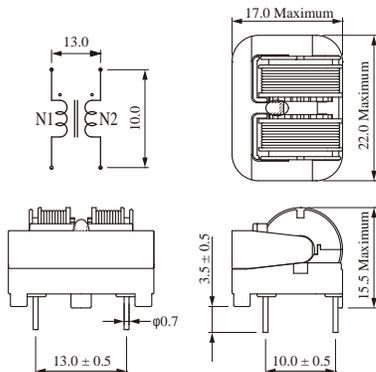

Dimensions

L	22mm MAX
T	17mm MAX
H	15.5mm MAX
LL	3.5mm +/-0.5mm
S	13mm +/-0.5mm

Packaging Specifications

Packaging:	Tray
Packaging Quantity:	300
Weight:	10 g

General Information

Series:	SSHB10H
Style:	Through-Hole
RoHS:	Yes
Notes:	Marking: 05 Lot No.
Miscellaneous:	Temperature Rise Maximum: 55 K

Specifications

Voltage AC:	250 VAC
Inductance:	21.2 mH (10 kHz)
Current:	500 mA
Temperature Range:	-25/+130°C
DC Resistance:	1.7 Ohms