



PLASTIC PIPE CUTTERS

Cut your PVC pipes with ease



Lightweight and robust

High-strength magnesium alloy body. Up to 35% lighter than a steel tool.

Power and durability

PTFE-coated stainless steel blade for easy, straight penetration of all plastics, PVC, PER, PEX and multi-layer pipes. Optimized force transmission reduces cutting effort, even in thick pipes.

One-hand operation

The ergonomic design and strength of the tool mean you can keep 1 hand free! Indispensable for holding work with the other hand. Controlled work and preserved balance.

Ingenious and practical

Quick and safe blade change in less than 10 seconds, without using other tools!

(Applies to 64026, 64035, 64042 and 64063 clamps)

Simple, fast and safe

The blade fits inside the magnesium alloy body.

The cutting edge won't get damaged in the toolbox, and there's no risk of injury when gripping the pipe cutter.




Reference	Designation	Packaging	EAN13
64026	EASYCLIP PIPE CUTTER FLEXIBLE 26MM	1	3700333202801
64035	EASYCLIP PIPE CUTTER FLEXIBLE 35MM	1	3700333202825
64028	EASYCLIP PIPE CUTTER FLEXIBLE AND THIN WALL 28MM	1	3700333202887
64042	EASYCLIP PIPE CUTTER PVC-PER NETWORK 42MM	1	3700333202849
64063	EASYCLIP PIPE CUTTER PVC-PER NETWORK 63MM	1	3700333202863
64001	STAINLESS STEEL COATED BLADE FOR PIPE CUTTER 26MM	1	3700333202818
64002	STAINLESS STEEL COATED BLADE FOR PIPE CUTTER 35MM	1	3700333202832
64005	STAINLESS STEEL COATED BLADE FOR PIPE CUTTER 28MM	1	3700333202900
64003	STAINLESS STEEL COATED BLADE FOR PIPE CUTTER 42MM	1	3700333202856
64004	STAINLESS STEEL COATED BLADE FOR PIPE CUTTER 63MM	1	3700333202870

ERKO-TOOLS-TV

Scan this code to watch a tutorial video on these products!



PLASTIC PIPE CUTTERS

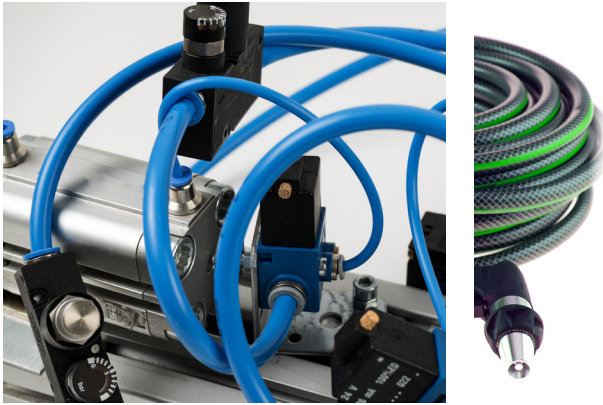

ERKO 64026 AND 64035 FOR FLEXIBLE HOSES

Perfect grip and cutting edge for fast, precise cutting of flexible hoses: compressed air, hydraulics, pneumatics, irrigation, underfloor heating.

64026


64035



Up to 26 mm



Up to 35 mm

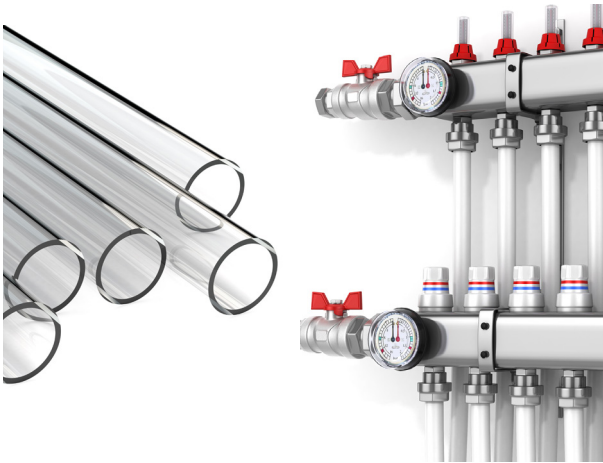

ERKO 64028 FOR FRAGILE, HARD-TO-CUT PIPES

Bevelled cutting edge and ball-bearing shaft. For perfect tube penetration. Cuts without tube deformation. Ideal for fragile, thin-walled tubes, brittle tubes, precise assemblies. Pneumatic and hydraulic networks, plumbing and heating fittings, chemicals.

64028



Up to 28 mm



ERKO 64042 ET 64063 FOR PVC - PER NETWORKS DRAINAGE AND SANITARY SYSTEMS.

A powerful grip and perfectly positioned blade for straight, fast and precise cuts in PVC and PER pipes.

The 63 mm model features a locking pawl to secure pipes with diameters under 50 mm, enabling the blade to attack small pipes with point, without crushing.

64042

64063



Up to 42 mm



Up to 63 mm

PLASTIC PIPE CUTTERS



ERKO 64127 PPR/PER/PVC/PE PIPE CUTTER FROM 50 TO 127 MM

- Lightweight and robust:** Magnesium/Aluminium alloy injected body
 - For all plastics:** PPR, PE, PVC, PER , multilayer ...
 - High-capacity:** from 50 to 127 mm diameter.
 - Fast:** injected ZAMAC knob and collar with rapid-feed system.
 - Straight cut:** 3 clamping rollers, 1 of which can be positioned according to diameter: for perfect hold of the tube during cutting.
 - Clean cut:** 360° integrated, retractable deburrer.
 - EASY-CLIP:** no-tool quick-change wheel.
- Supplied with a 51 mm cutting wheel, for cutting tubes up to 20 mm thick.



Reference	Designation	EAN13
64127	PLASTIC/MULTILAYER PIPE CUTTER 127MM	3700333202917
64006	51MM WHEEL FOR PVC PIPE CUTTER	3700333201675



ERKO 64170 PPR/PER/PVC/PE PIPE CUTTER FROM 100 TO 170 MM

- Lightweight and robust:** Magnesium/Aluminium alloy injected body
 - For all plastics:** PPR, PE, PVC, PER , multilayer ...
 - High-capacity:** from 100 to 170 mm diameter.
 - Fast:** injected ZAMAC knob and collar with rapid-feed system.
 - Straight cut:** 3 clamping rollers, 1 of which can be positioned according to diameter: for perfect hold of the tube during cutting.
 - Clean cut:** 360° integrated, retractable deburrer.
 - EASY-CLIP:** no-tool quick-change wheel.
- Supplied with a 51 mm cutting wheel, for cutting tubes up to 20 mm thick.



Reference	Designation	EAN13
64170	PLASTIC/MULTILAYER PIPE CUTTER 170MM	3700333202924
64006	51MM WHEEL FOR PVC PIPE CUTTER	3700333201675