

Vernier and Dial Calipers

Pocket Vernier Caliper

DIN 862

- with thumb locking
- for left-handed use
- stainless steel, hardened
- graduation in mm/inch, laser engraved scale
- scale and vernier satin chrome finish
- jaws finely ground and lapped
- mono block vernier




ART No	mm / inch	mm bottom	inch top	mm	mm	flat	CC
201027	150 / 6	0.05	1/128	40	16	flat	on request

Small Pocket Vernier Caliper

DIN 862

- for crafts, also very popular promotional item
- stainless steel, hardened
- scale and vernier satin chrome finish, laser engraved scale
- jaws finely ground and lapped
- with fixing screw

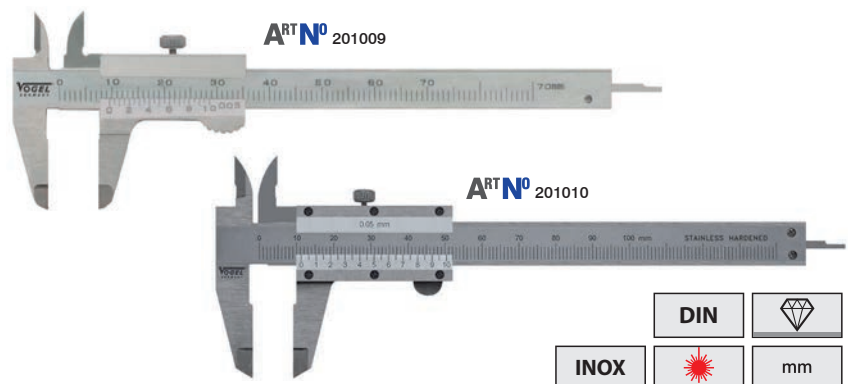


ART No	mm	mm	mm	mm	flat	CC
201009	70	0.05	20	9	flat	on request
201010	100	0.05	30	13	flat	on request

Dial Caliper • IP40

DIN 862

- economic model, shock proof mechanics
- for fast and accurate reading
- stainless steel, hardened
- measuring rail matt chrome finish, laser engraved scale
- jaws finely ground and lapped
- dust proof housing, flat depth gauge
- with thumb roll for fine adjustment
- with fixing screw

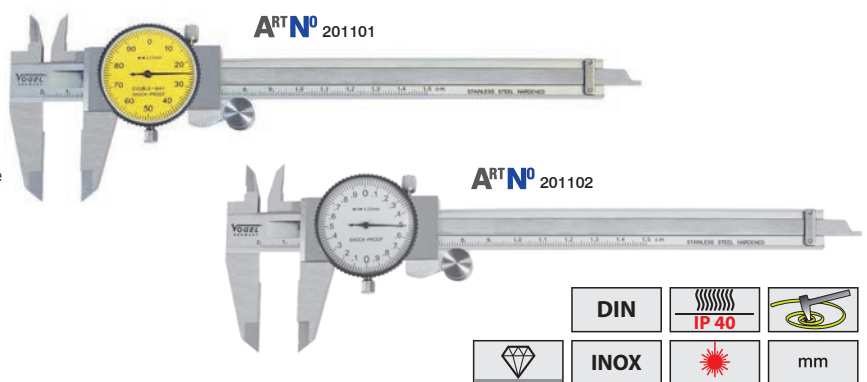

ART No	mm	mm	mm	mm	mm	flat	CC
201101	150	0.01	1	40	16.5	flat	on request
201108	200	0.01	1	48	19.5	flat	on request
201109	300	0.01	1	62	22	flat	on request
201102	150	0.02	2	40	16.5	flat	on request
201103	200	0.02	2	48	19.5	flat	on request
201104	300	0.02	2	62	22.0	flat	on request