




TAH2430G

ERGO™ Snipe Nose Pliers with Safety Ring



PRODUCT DETAILS

- Snipe nose pliers developed according to the scientific ERGO™ process
- ERGO™ handles with two-component combination, thermoplastic surface on tough polypropylene to give a superior grip
- Slim semicircular shaped and serrated jaws
- Equipped with a return spring featuring an on/off function
- High performance alloy steel
- Phosphate finish, anti-corrosion treated
- ISO 5745
- Tips give a good grip and improved accessibility in confined spaces
- Sharp edges for cutting softer material such as copper and plastic insulated wire
- Suitable for working at height
- Permanent stainless steel ring attached directly to the body of the plier maintains user ergonomics and full functionality
- Colour plate with maximum weight for a right matching with the lanyard
- Safety ring is attached to the metallic part to avoid losing handle
- According to DROPS best practices

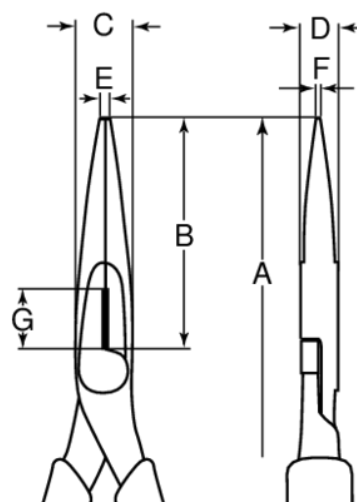





Follow the Fish!







PRODUCT ATTRIBUTES

Product: **TAH2430G-160**

A	160 mm	B	51 mm	C	16,5 mm
D	8,8 mm	E	3 mm	F	2.5 mm
G	12 mm	 Cu	3.0 mm	 Fe	1.8 mm
 Fe+	1.6 mm	 g	167 g		

Product: **TAH2430G-200**

A	200 mm	B	72 mm	C	17 mm
D	9 mm	E	3,2 mm	F	3 mm
G	12 mm	 Cu	3.0 mm	 Fe	1.8 mm
 Fe+	1.6 mm	 g	180 g		

Follow the Fish!

