


Chiavi a forchetta semplici a percussione zincate

DIN 133

- Utilizzabili a percussione con mazza o martello pneumatico

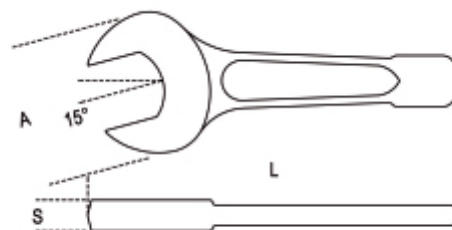

		art.	mm				
		000580024	58 24	24	177	52,0	15,0
		000580027	58 27	27	180	58,0	16,0
		000580030	58 30	30	190	66,0	17,0
		000580032	58 32	32	190	68,0	17,0
		000580034	58 34	34	200	71,0	18,0
		000580036	58 36	36	215	78,0	19,0
		000580041	58 41	41	235	90,0	19,0
		000580046	58 46	46	255	100,0	21,0
		000580050	58 50	50	275	110,0	21,0
		000580055	58 55	55	300	120,0	23,0
		000580060	58 60	60	320	130,0	23,0
		000580065	58 65	65	342	142,0	28,0
		000580070	58 70	70	375	156,0	30,0
		000580075	58 75	75	375	164,0	30,0
		000580080	58 80	80	408	175,0	33,0
		000580085	58 85	85	408	175,0	33,0
		000580090	58 90	90	445	197,0	38,0
		000580095	58 95	95	445	197,0	38,0
		000580100	58 100	100	485	215,0	45,0
		000580105	58 105	105	485	215,0	45,0
		000580110	58 110	110	510	235,0	47,0
		000580115	58 115	115	510	235,0	47,0
		000580120	58 120	120	545	255,0	50,0
		000580125	58 125	125	545	255,0	50,0
		000580130	58 130	130	575	275,0	55,0
		000580135	58 135	135	575	275,0	55,0
★		000580140	58 140	140	575	275,0	55,0
★		000580145	58 145	145	640	305,0	60,0
★		000580150	58 150	150	640	305,0	60,0
★		000580155	58 155	155	640	305,0	60,0
★		000580160	58 160	160	640	305,0	60,0
★		000580165	58 165	165	715	342,0	70,0
★		000580170	58 170	170	715	342,0	70,0
★		000580175	58 175	175	715	342,0	70,0
★		000580180	58 180	180	715	342,0	70,0
★		000580185	58 185	185	715	342,0	70,0
★		000580190	58 190	190	800	392,0	78,0
★		000580195	58 195	195	800	392,0	78,0
★		000580200	58 200	200	800	392,0	78,0
★		000580210	58 210	210	800	392,0	78,0
★		000580220	58 220	220	800	392,0	78,0
★		000580230	58 230	230	800	392,0	78,0