

Datasheet

## RS Pro P13.5s Filament Indicator Lamp, Clear, 3.6 V, 750 mA, 15h

RS Stock No: **655-9132**



### Product Details

RS Pro P13.5s filament indicator lamp comes with clear lens and P13.5s prefocus base. It is filled with Krypton gas for high brightness. It has a voltage rating of 3.6 V and current rating of 750 mA. The lamp has 15 h life.

### Features and Benefits

- Olive shape B3 - 11 mm glass
- Alternative to vacuum types
- P13.5s prefocus base




**Specifications:**

Current Rating	750 mA
Diameter	11.3 mm
Lamp Base	P13.5s
Lamp Size	B3 1/2
Length	29 mm
Lens Colour	Clear
Life Hours	15 h
Luminosity	16 lm
Voltage Rating	3.6 V

RS Stock No.

6559132

*DRAWING - I*

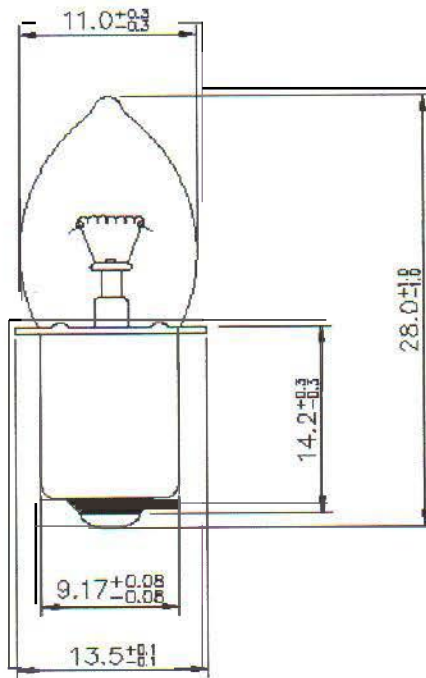

Unit : mm

1. Structure	Bulb Type	B3 1/2
	Bulb Diameter	Ø 11.3Max.
	Length	29.0Max
	Base Type	P13.5s KRP
2. Design Characteristics	Voltage	3.6V
	Amperage	750mA± 10%
	Gas Type	Krypton gas-filled
	M.S.C.P.	1.27CP±20%
	Life Hours	15Hrs