



Brand of NTN corporation

Technical data

USSP.208

Bearing units




Grey cast housing, radial insert ball bearing with socket set screws, single lip seal

KIT CONTENT

US.208.G2, SP208-210/80

VISUAL (S)

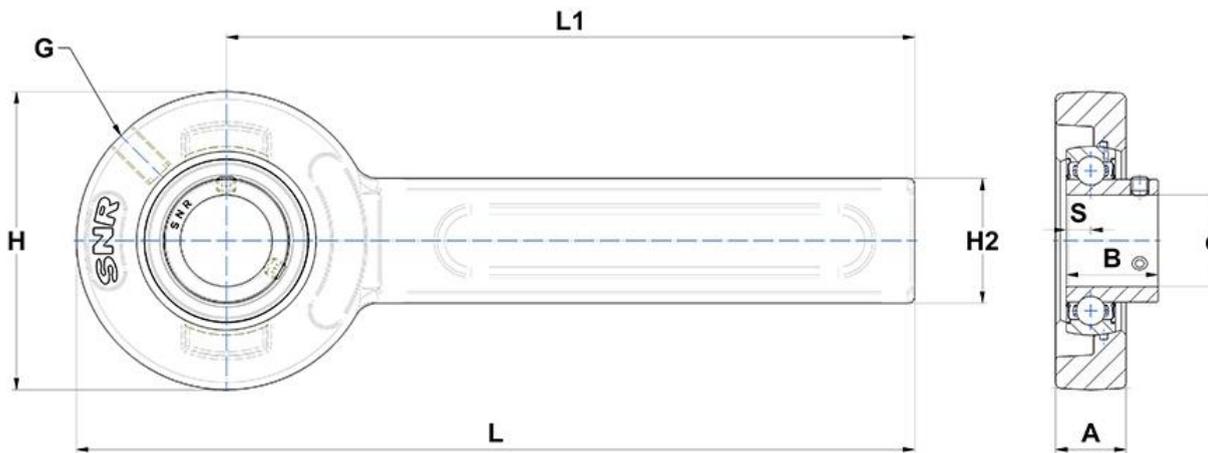

PRODUCT DEFINITION

Brand	SNR
A - Housing width	31 mm
B - Width of Inner Ring	34 mm
d - Shaft diameter	40 mm
G - Grease fitting	R1/8"
H - Housing length, width or diameter	120 mm



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
 S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
 SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT DEFINITION

H2 - Housing height / width	61 mm
L - Housing length	320 mm
L1 - Distance attachment end face to bearing centerline	260 mm
S - Distance front side/bearing centre	9 mm

PRODUCT PERFORMANCE

C - Dynamic load rating	29600000 mN
C0 - Static load rating	18200000 mN
Operating temperature min.	253,15 °K
Operating temperature max.	373,15 °K

OTHER FEATURES

Stretcher frame 2	SPR21
Stretcher frame 3	SPR22
Stretcher frame 4	SPR24
Mass	4,01 kg
Recommended tightening torque for set screw	11.5 N-m

