


RM-ECv Controller

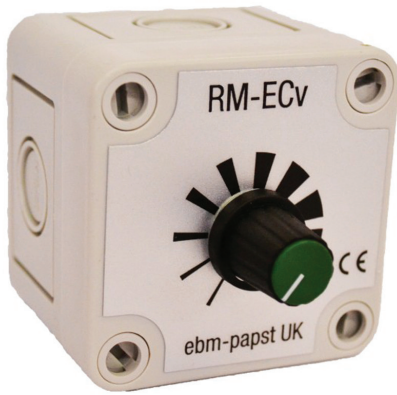


The RM-ECv controller is for use with the full range of ebm-papst EC fans. Powered by the 10V DC output from the motor, it provides infinitely variable, manual speed control between 0% and 100%.

The maximum and minimum speeds can be varied during commissioning to limit the maximum speed and/or restrict the lower speed.

| | Supply Voltage | Maximum Ambient Temperature | IP Rating | Height | Width | Depth | |
|------------------|----------------|-----------------------------|-----------|--------|-------|-------|--|
| Part Number | VDC | °C | | mm | mm | mm | |
| RM-ECv | 10 | 50 | 54 | 65 | 50 | 84 | |
| CN1063 (Unboxed) | 10 | 50 | 00 | 36 | 36 | 50 | |

- Can control multiple fans running at the same speed
- Stepless control knob for infinitely variable speed setting
- Cable entries 4 x M16 or M20
- 4mm mounting holes
- No separate power supply required

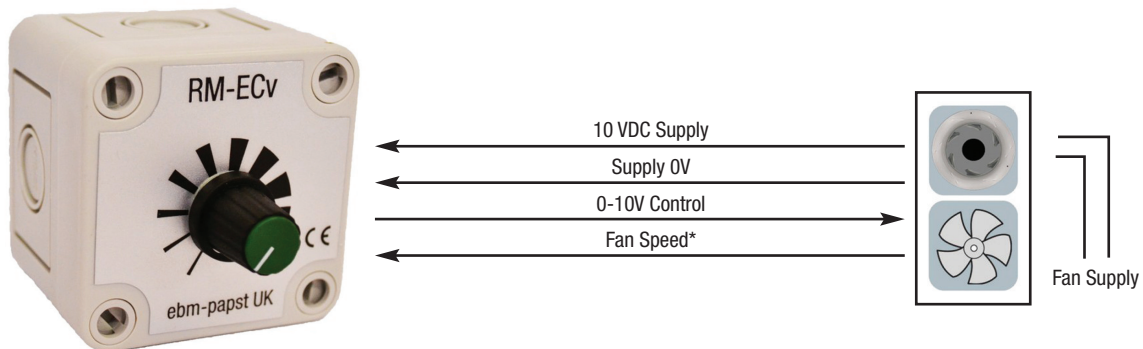

*Optional