


## Features

- Excellent UV resistance
- UL approved Nylon 66, 94V-2
- Color: Natural, other special color available request.
- Feature: Low Smoke and Halogen Free cable tie suitable for various industry, also household DIY and gardening.
- Easy to thread and install.
- Ideal for use outdoors.

## RS PRO Cable Ties

RS Stock No.: 8111537

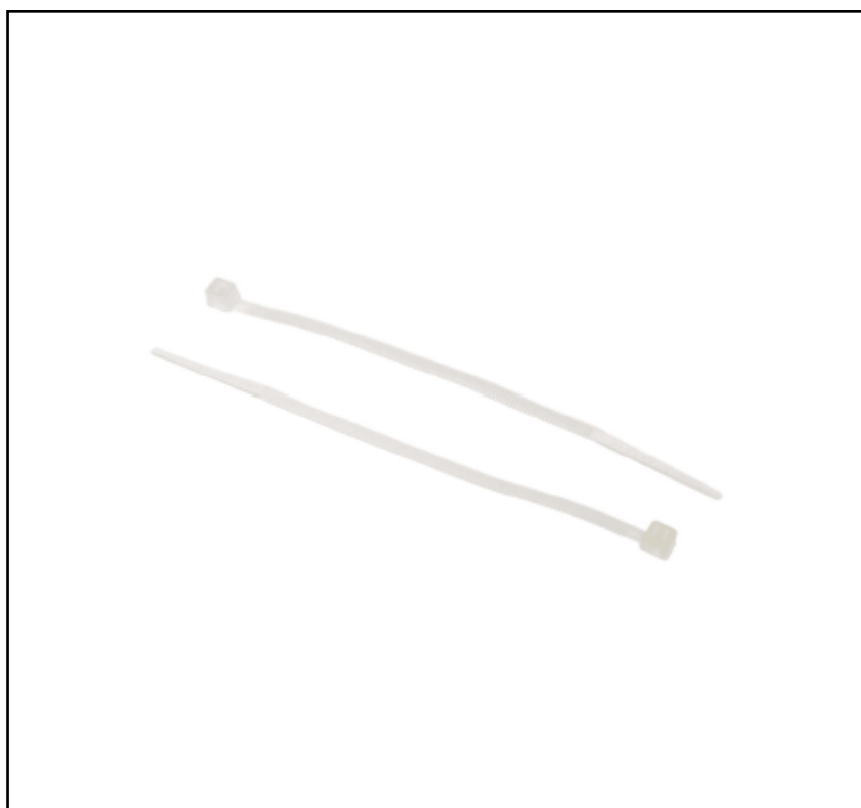

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

## Product Description

RS PRO cable ties are a type of fastener used for holding items together, most commonly electrical cables or wires. These cable ties are made from Nylon 66 (also known as nylon 6.6) and are weather resistant so can be used in outdoor applications. These ties are a one-piece, self-locking fastener and function like straps to keep cables tidy. They are available in a range of sizes. The design of a cable tie includes a head which provides the slot for the tape to be pulled through, to make a loop. The cable can be pulled through the slot until the preferred loop is achieved and then the excess cable can be cut off.

## General Specifications

|                               |                    |
|-------------------------------|--------------------|
| Type                          | Non-Releasable     |
| Colour                        | Natural            |
| Material                      | Nylon 66           |
| UV Resistant                  | Weather Resistant  |
| Minimum Operating Temperature | -40°C              |
| Maximum Operating Temperature | 85°C               |
| Fire Behaviour                | Self-Extinguishing |
| Quantity                      | 250                |

## Mechanical Specifications

|                                       |                      |
|---------------------------------------|----------------------|
| Length                                | 300mm / 11-7/8"      |
| Width                                 | 4.8mm / 0.19"        |
| Min. Loop Tensile Strength(lbs/kgf/N) | 50lbs / 22kgf / 222N |
| Maximum Bundle Dia.                   | 83mm                 |

## Approvals

|               |                    |
|---------------|--------------------|
| Standards Met | UL, RoHS, SVHC, HF |
|---------------|--------------------|

