




ENGLISH

Datasheet

# RS Pro Dimmable Drive 1200mA (50w LED Panel)

RS Stock No: 122-2831

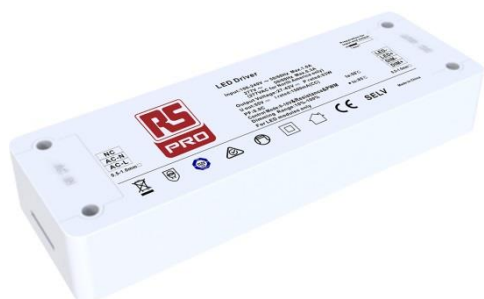

This isolated LED driver is designed for class II LED luminaires.

**Category:** 0-10V/PWM plastic case dimmable version.

**Product properties:** active PFC, high PF, high efficiency, low THD, 0-10V/PWM dimmable.

**Application:** commercial, residential and decorative lighting.

## Typical Properties

AC100-277V, DC 27-42V, 1200MA

1-10v dimmer or resistance dimmer ,

Dimmer range: 10-100%

Power factor:  $\geq 0.93$

Efficiency :  $\geq 82\%$

Product weight: 250 g

Product size in 64 x 193 x31 mm

CE , SAS, ENEC, CB, UL certificate

