



# DTH10

## Digital Thermo-Hygrometer

### ***TEMPERATURE AND HUMIDITY READINGS IN A CONVENIENT PEN-STYLE CASE***

- Temperature from 14° to 122°F (-10° to 50°C)
- Humidity from 5 to 95% RH
- Fast, accurate electronic sensor
- Displays relative humidity and temperature at the same time
- MIN/MAX Record
- Data Hold
- Auto power-off



# DTH10 • Digital Thermo-Hygrometer


The DTH10 has an excellent combination of features, conveniently packaged and easy to use.

## The DTH10 has the following features:

- Temperature in °F or °C (14° to 122°F / -10° to 50°C)
- 5 to 95% relative humidity (RH)
- Fast, accurate electronic sensor
- Displays relative humidity and temperature at the same time
- MIN/MAX record
- Data hold
- Auto power-off
- One year limited warranty

## Specifications

Power supply	1 lithium CR2032 # V battery
Battery life	150 hours
Sensor	Electronic capacitance polymer film sensor
Temperature range	14° to 122°F (-10° to 50°C)
Humidity range	5 TO 95% RH
Accuracy	±5% for 5 to 95% RH at 25°C and ±1°C from -10° to +45°C
Resolution	0.1°F (0.1°C)
Dimensions	6.5" x 1.5" x .5" (17.54 cm x 4.2 cm x 1.6 cm)

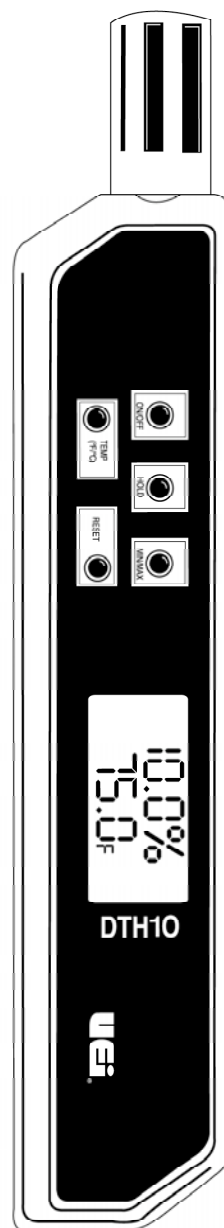

Distributed By:



1-800-547-5740 • Fax: (503) 643-6322  
www.ueitest.com • Email: info@ueitest.com

### IN CANADA

Vancouver: Phone: 1-877-475-0648 • (604) 278-4511 • Fax: (604) 278-8299  
Toronto: Phone: 1-877-475-0648 • Fax: (905) 238-5117

### IN EUROPE

Phone: +44 1707 375550 • Fax: +44 1707 393277

