

0 601 066 H00 – GCL 2-50 CG

Material number	0 601 066 H00	0 601 066 H70
EAN	3165140865654	3165140894920
Retail price	280.00 GBP	
Discount Group	000	GDM
1 x battery GBA 12V 2.0 Ah 1 600 Z00 02X	✓	✓
Ceiling clamp	✓	✓
GCL 2-50 C/CG Inlay 1 1 608 M00 C1T	✓	✓
GCL 2-50 C/CG Inlay 2 1 608 M00 C1U	✓	✓
L-BOXX 136 1 600 A00 1RR	✓	✓
Laser target plate	✓	✓
Protective bag	✓	✓
Quick charger GAL 1230 CV 1 600 A00 R44	✓	
Quick charger GAL 1230 CV 1 600 A01 16B		✓
Rotating mount RM2 0 601 092 700	✓	✓




Technical data

Description

Applications	Construction work Levelling work Suspended ceiling installation Tiling Point transfer
Outdoor applications	Pulse mode Alignment
Indoor applications	Interior fitting work

Technical data

Laser diode	500 – 540 nm, < 10 mW 630 – 650 nm, < 1mW
Operating temperature	-10 – 50 °C
Storage temperature	-20 – 70 °C
Laser class	2
Working range	20 m
Working range with receiver	50 m
Accuracy	± 0.3 mm/m
Working range of laser points, max.	10 m (top) 10 m (bottom)
Self-levelling range	± 4°
Dust and splash protection	IP 54
Operating time (max.)	10 h (Li-Ion) and 4 h (4 x AA) in cross-line and point operation 13 h (Li-Ion) and 6 h (4 x AA) in cross-line operation 15 h (Li-Ion) and 12 h (4 x AA) in line operation 60 h (Li-Ion) and 32 h (4 x AA) in point operation
Tripod thread	1/4"
Weight, approx.	0.6 kg
Colour of laser line	green
Projection	2 lines / 2 points
Plumb point accuracy	± 0.7 mm/m

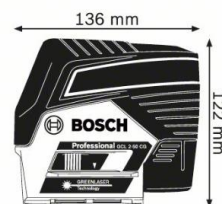

Sales information

Positioning

- Supreme visibility connected with smart functions

User benefit

- Green horizontal and vertical lines for maximal visibility
- Bluetooth® connection to smartphone for remote control and adjustment of the tool
- Dual Power Source: Can be operated both with 12 V-Li-ion battery and with standard alkaline batteries

Other features

- Horizontal and vertical laser lines and two centred plumb points with optimal visibility
- Precise positioning of the laser lines around the plumb points – motorised positioning with RM 3 Professional (optional), using an app or remote control or manual positioning with RM 2 Professional
- High visibility of the laser lines with a working range of 20 m (without receiver)
- Working range of 50 m with the LR 7 Professional receiver (optional)
- Pendulum lock ensures safe transport