


Datasheet

Recessed Countersunk Machine Screws
 Stainless Steel A2-304
 DIN 965

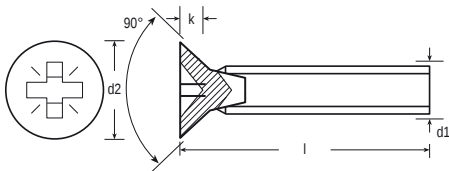

| d1 | M1.6 | M2 | M2.5 | M3 | M3.5 | M4 | M5 | M6 | M8 |
|------------|------|------|------|------|------|------|------|-------|-------|
| d2 | 3.00 | 3.80 | 4.70 | 5.60 | 6.50 | 7.50 | 9.20 | 11.00 | 14.50 |
| k max. | 0.96 | 1.20 | 1.50 | 1.65 | 1.93 | 2.20 | 2.50 | 3.00 | 4.00 |
| Recess no. | 0 | 1 | 1 | 1 | 2 | 2 | 2 | 3 | 4 |

Please view our full range listing below

| RS Stock No | Size (mm) | RS Stock No | Size (mm) | RS Stock No | Size (mm) | RS Stock No | Size (mm) | RS Stock No | Size (mm) |
|-------------|-----------|-------------|-----------|-------------|-----------|-------------|-----------|-------------|-----------|
| 1795664 | M1.6 × 3 | 1795673 | M2.5 × 5 | 9141771 | M3 × 16 | 9141797 | M5 × 8 | 529040 | M6 × 20 |
| 1795665 | M1.6 × 4 | 1795674 | M2.5 × 6 | 528968 | M3 × 20 | 9141807 | M5 × 10 | 529056 | M6 × 25 |
| 1795666 | M1.6 × 5 | 1795675 | M2.5 × 8 | 9141775 | M3 × 25 | 529006 | M5 × 12 | 9141829 | M6 × 30 |
| 1795667 | M1.6 × 6 | 1795676 | M2.5 × 10 | | | 7976351 | M5 × 16 | 9141822 | M6 × 35 |
| | | 1795677 | M2.5 × 12 | 9141784 | M4 × 5 | 529012 | M5 × 20 | 9141826 | M6 × 40 |
| 9141759 | M2 × 4 | 1795678 | M2.5 × 16 | 7976349 | M4 × 6 | 529028 | M5 × 25 | 9141835 | M6 × 45 |
| 1795668 | M2 × 5 | 1795679 | M2.5 × 20 | 9141787 | M4 × 8 | 7976355 | M5 × 30 | 9141838 | M6 × 50 |
| 9141753 | M2 × 6 | 1795680 | M2.5 × 25 | 7976358 | M4 × 10 | 9141800 | M5 × 35 | | |
| 9141762 | M2 × 8 | | | 528974 | M4 × 12 | 9141804 | M5 × 40 | 9141832 | M8 × 25 |
| 1795670 | M2 × 10 | 9141765 | M3 × 5 | 528980 | M4 × 16 | 9141813 | M5 × 50 | 9141841 | M8 × 30 |
| 1795671 | M2 × 12 | 528946 | M3 × 6 | 528996 | M4 × 20 | | | 9141844 | M8 × 40 |
| 1795669 | M2 × 16 | 9141769 | M3 × 8 | 9141781 | M4 × 25 | 9141816 | M6 × 10 | | |
| | | 9141778 | M3 × 10 | 9141790 | M4 × 30 | 529034 | M6 × 12 | | |
| 1795672 | M2.5 × 4 | 528952 | M3 × 12 | 9141793 | M4 × 40 | 9141810 | M6 × 16 | | |