

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [2196641053](#)
Status: **Active**
Overview: [Off-the-Shelf Cable Assemblies](#)
Description: KK 396-to-KK 396 Off-the-Shelf (OTS) Cable Assembly, 3.96mm Pitch, Single Row, 300.00mm Length, 5 Circuits, Natural

Documents:

[Drawing \(PDF\)](#)

[Datasheet \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Cable Assemblies
Series	219664
Application	Power, Wire-to-Board
Assembly Configuration	Dual Ended Connectors
Connector to Connector	KK 396-to-KK 396
Overview	Off-the-Shelf Cable Assemblies
Product Name	KK 396
Taxonomy	Power and Signal Cable Assembl
Type	Discrete Wire Assembly
UPC	195842810563

Physical

Cable Length	300.00mm
Circuits (Loaded)	5
Color - Resin	Natural
Gender	Female-Female
Lock to Mating Part	Yes
Material - Metal	Brass
Material - Plating Mating	Tin
Material - Resin	Polyester
Net Weight	19.024/g
Number of Rows	1
Packaging Type	Bag
Pitch - Mating Interface	3.96mm
Single Ended	No
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	2.79mm max.
Wire Size AWG	18
Wire/Cable Type	UL 11028


Electrical

Current - Maximum per Contact	13.0A
-------------------------------	-------

Material Info

Reference - Drawing Numbers

Sales Drawing	2196641052-000
---------------	----------------

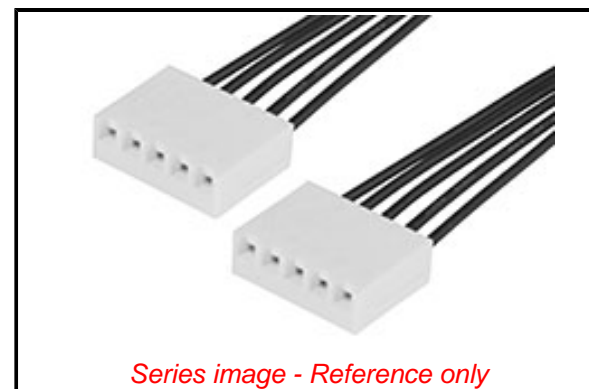

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2022)4187-DC (10
June 2022)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[219664](#) Series

Mates With

KK 396 Header [41791](#) , [41792](#) , [41671](#) ,
[41672](#) , [41661](#) , [41662](#)