


Features

- ANSI MC96.1
- Good temperature resistance (not suitable in fluids)
- Fast response, welded exposed junction
- Bare tails

RS PRO Glassfibre insulated ANSI Exposed Junction Thermocouple with Bare Tails - Type K

RS Stock No.: 0652760

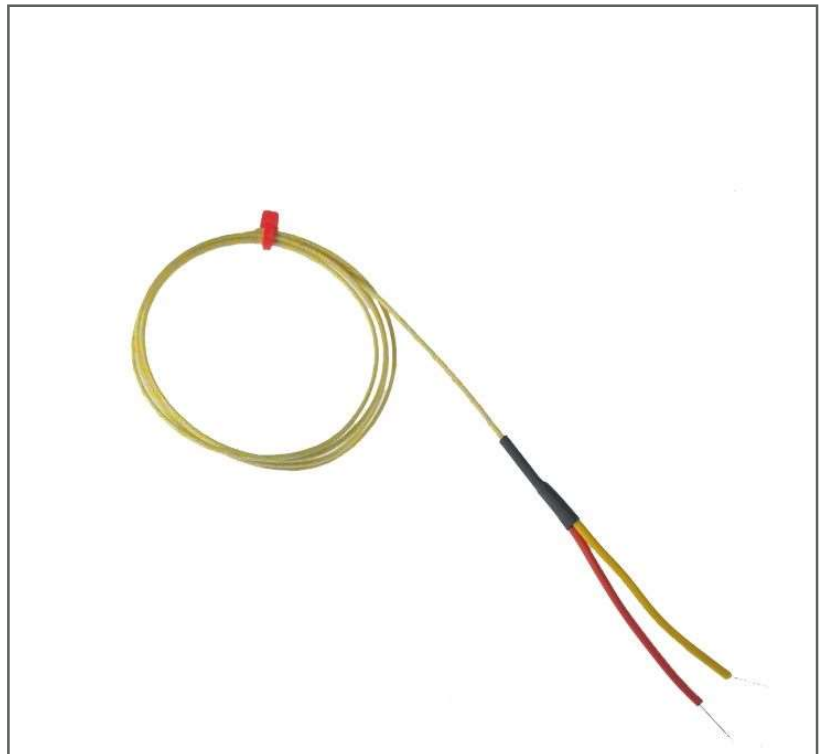

RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

Product Description

Exposed junction thermocouples are often used in applications where fast response times are crucial, such as in research laboratories, semiconductor manufacturing, and certain industrial processes.

General Specifications

Thermocouple Type	Type K
Temperature Measurement Range	-60°C to 350°C (short periods up to 400°C)
Construction	Fast response, welded exposed junction
Measuring Junction	Exposed
Standards Met	ANSI
Application	Good temperature resistance (not suitable in fluids)

Mechanical Specifications

Termination	Bare Tails
Length	0.3m (0.98ft)
Cable Insulation	1/0.3mm glassfibre insulated flat pair cable

Approvals

Declarations	RoHS
--------------	------

Similar Products

RS Stock#	RS Stock#	RS Stock#	RS Stock#	RS Stock#	RS Stock#
0.3m (0.98ft)	1m (3.3ft)	2m (6.56ft)	3m (9.84ft)	5m (16.4 ft)	10m (32.8ft)
0652760	8479675	8479684	2318481	8479700	8479732