

Accessory, Helawrap, black, 50pcs. (HWBASE)

Art.-No. 161-64015 | HWBASE-PA66HIRHS-BK | 



- Mounting plates can be fixed with screws, cable ties or adhesive
- Can be used to mount any size HWClip

HF ✓

RoHS ✓

More products in this product group:

[Accessories for retaining Helawrap Open Cable Cover >](#)

This product is part of:

[Samples Helawrap Accessories](#)




Application	To complete the Helawrap cable management system various Helawrap Clips in compatible sizes are available. The mounting clips can be combined and adjusted individually. Attached to a mounting base the assembly can be screw mounted or directly stuck to the surface.
Colour	Black (BK)
Fixation Method	screw-hole
Material	Polyamide 6.6, high impact modified, heat stabilised (PA66HIRHS)
PART DESCRIPTION	HWBASE-PA66HIRHS-BK
Pack Content	50 pcs.
Package Content packed in	bag
Product Family	HWBase
Product Group	Acessories for retaining Helawrap Open Cable Cover
Type	HWBASE

Product Dimensions

Length (L)	38 mm
Width (W)	38 mm

Specifications

ELV compliant (Article 4 - 2)	YES
Flammability	UL 94 HB
Halogen-free	Yes
Hazardous Goods	No
Melting Point	+284 °F (+140 °C)
Operating Temperature	-40 °C to +105 °C
ROHS compliant	Yes
Specifications	HF✓ RoHS✓

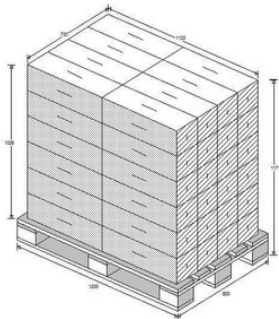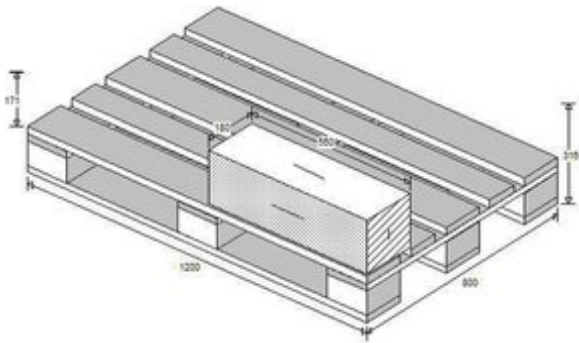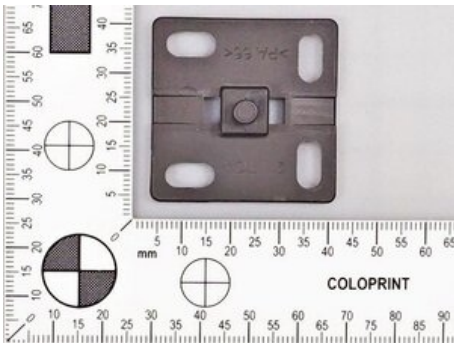

GTIN-13 / EAN	4031026575513
Packaging 1 - Height (m)	0.02 m
Packaging 1 - Length (m)	0.25 m
Packaging 1 - Qty	50
Packaging 1 - Type	bag
Packaging 1 - Volume (m³)	0.0011 m³
Packaging 1 - Weight (kg)	0.161729 kg
Packaging 1 - Width (m)	0.22 m
Packaging 3 - Height (m)	0.171 m
Packaging 3 - Length (m)	0.56 m
Packaging 3 - Qty	1000
Packaging 3 - Type	box
Packaging 3 - Volume (m³)	0.0172 m³
Packaging 3 - Weight (kg)	3.57858 kg
Packaging 3 - Width (m)	0.18 m
Packaging 4 - Height (m)	1.164 m
Packaging 4 - Length (m)	1.2 m
Packaging 4 - Qty	48000
Packaging 4 - Type	pallet
Packaging 4 - Volume (m³)	1.117 m³

More Information

UNSPSC Key	39131604
------------	----------