



Connector Location A

Connector Location B

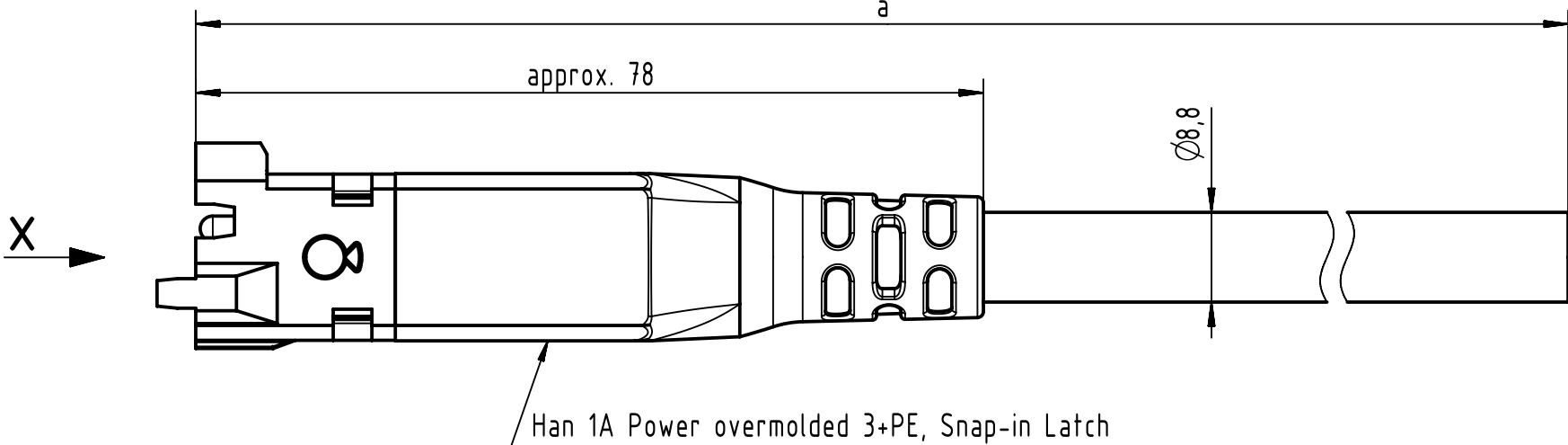


X
male

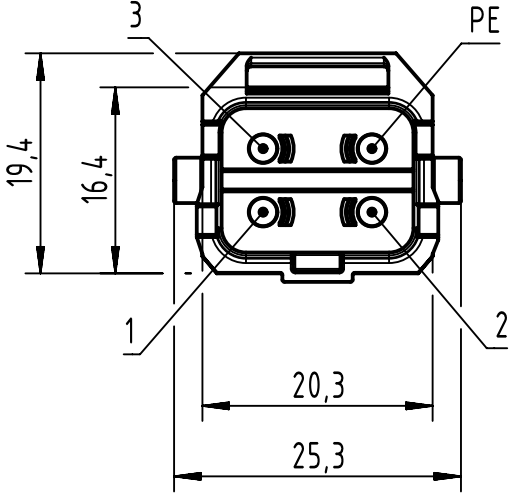

Loading Plan

1	wire 1
2	wire 2
3	wire 3
PE	green/yellow

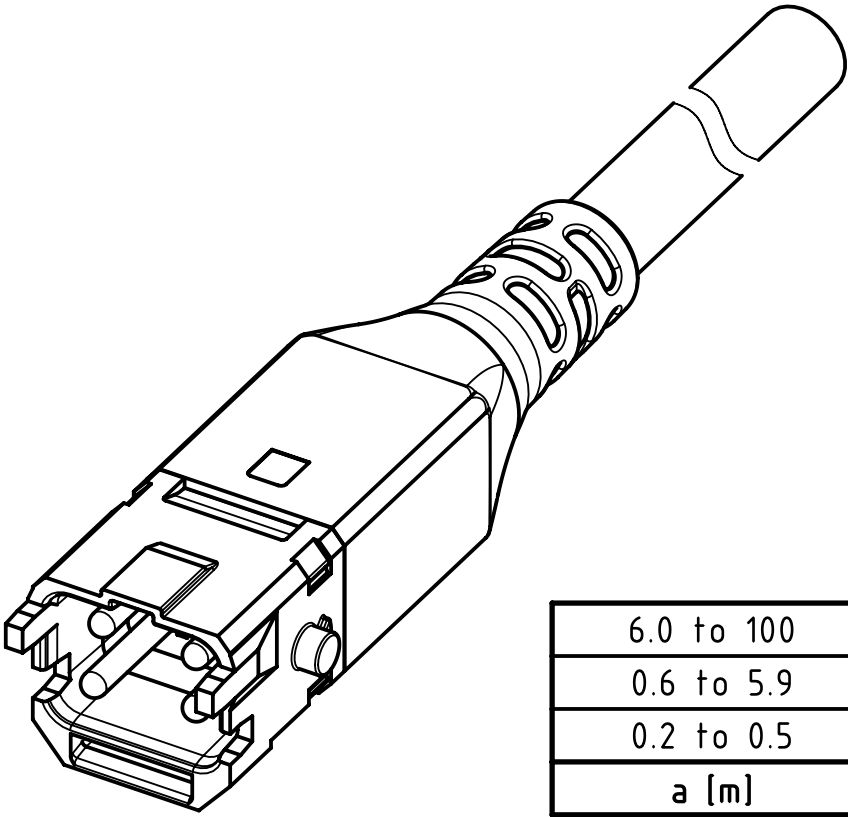

6.0 to 100	±1%
0.6 to 5.9	+0.04
0.2 to 0.5	+0.02
a [m]	Tolerance

length in "1m" step	100	XXX=000
	99	XXX=990
	.	.
	12	XXX=120
length in "0.1m" step	11	XXX=110
	10	XXX=100
	9.9	XXX=099
	9.8	XXX=098
	.	.
	0.5	XXX=005
	0.4	XXX=004
	0.3	XXX=003
	0.2	XXX=002
Step	a [m]	XXX

NOTE:
* Silver plated contacts
* Protection level: IP66/67
Temperature range:
- Fixed installation: -40°C ... +80°C
- Dynamic installation: -5°C ... +70°C

Ölflex 409 P 4G1,5mm², PUR, black	33400400204XXX
Type of cable	Part no.

All Dimensions in mm		Tech. Character.		Free size tol.		According to production drawing	
	All rights reserved	Created by COSTEA Costea	Inspected by COSTEA Costea	Standardisation BANCUI Banciu	Date 2024-04-24	State Final Release	
	Department HCS - GPM	Title Han 1A OM 3+PE +latch m/- PUR				Doc-Key / ECM-Nr. 101132496/UGD/001/A 500000268092	
	HARTING Customised Solutions D-32339 Espelkamp	Type TB	Number 33400400204XXX			Rev. A	Page 1/1