


Geberit Mapress Stainless Steel elbow tap connector 90°



Example image

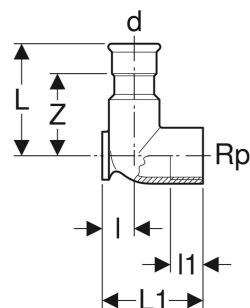

APPLICATION PURPOSES

- For cold and hot potable water
- For cooling and heating water without antifreeze agent
- For cooling and heating water with antifreeze agent
- For district heating water ≤ 120 °C
- For saturated steam ≤ 120 °C
- For service water and process water
- For treated water
- For rainwater with a pH value ≥ 5.5
- For grey and black water with a pH value ≥ 5.5
- For extinguishing water (wet)
- For extinguishing water (wet/dry, dry)
- For sprinklers (wet)
- For chemicals and technical liquids
- For compressed air (oil purity class 0–3)
- For negative pressure
- For inert gases (e.g. nitrogen)
- For industrial gases (e.g. acetylene, shielding gases)
- For technical building systems, industry and shipbuilding

CHARACTERISTICS

- Pressing indicator
- Leaky if unpressed
- Two fastening points
- Seal ring made of CIIR, black
- Pressing socket with transparent protection plug

TECHNICAL DATA

Product material CrNiMo steel 1.4401 (EN 10088)

Art. no.	DN	d, ø mm	Rp "	arc °	L cm	L1 cm	I cm	I1 cm	Z cm
33013	10 / 15	12	1/2	90	4.6	4.3	1.3	1.5	2.9
33403	12 / 15	15	1/2	90	5	4.3	1.3	1.5	3
33405	15	18	1/2	90	5	4.3	1.3	1.5	3

Art. no.	DN	d _e mm	R _p "	arc °	L cm	L ₁ cm	I cm	I ₁ cm	z cm
33407	20	22	3/4	90	5.4	5.1	1.7	1.6	3.3