 



Quick connector, 8/10 mm slot, 90°, cover cap



- Tie rod head rotated at a 90° angle to the connector sleeve
- Profile finishing: blind hole DI, DB11, DB17 or through-hole DI, D11, D17

## Product description

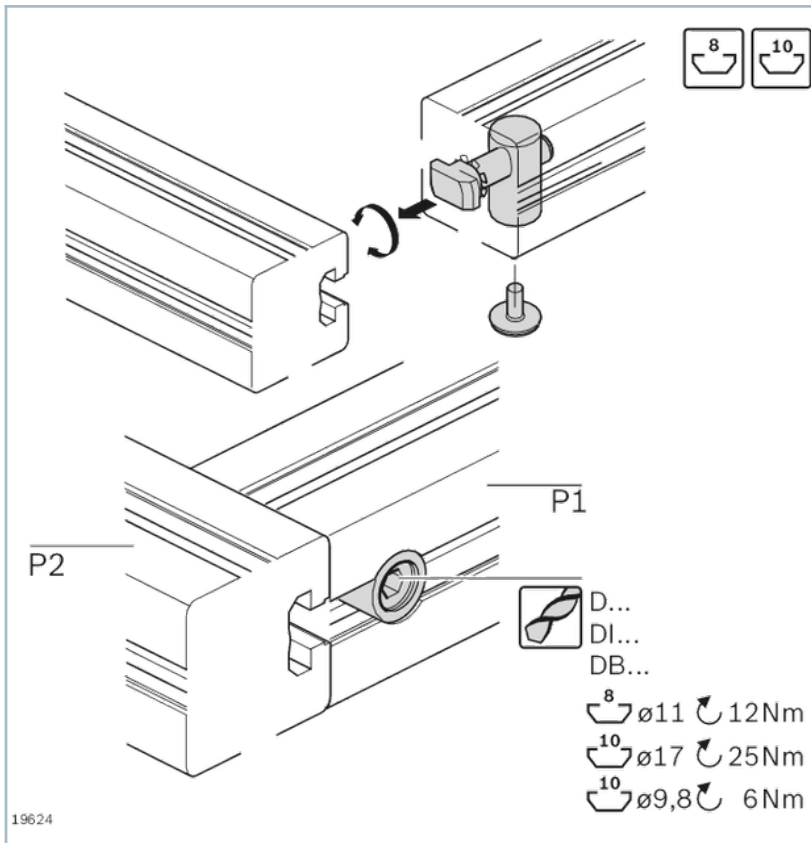


Connection elements, selection criteria

## Technical data


Nut	$F_{max}$	$M_{max}$
8/8	500 N	40 Nm
10/10	4000 N	140 Nm
10/10	800 N	50 Nm

## Dimensions

Quick connector, 8/10 mm slot, 90°

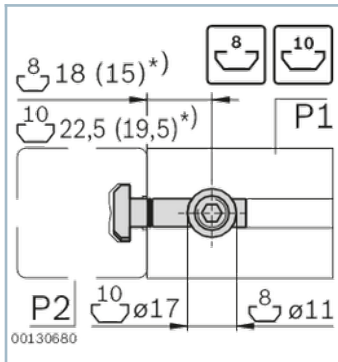

Quick connector, 10/10 mm slot, 90°, connector sleeve D = 9.8

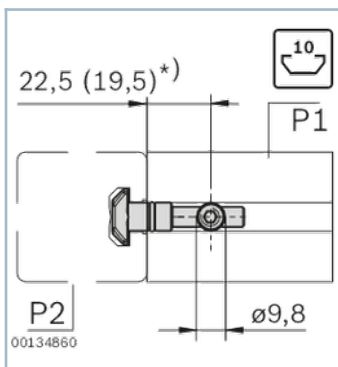

## Accessories


Recommended accessories

Anti-torsion element

Radial compensation

Drilling jig

Cap

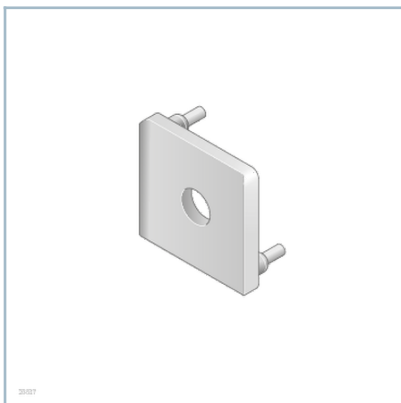

### Radial compensation

- To avoid gaps and sharp edges on T-connections between two profiles using a central bolt or quick connector (note spacing of hole from the face of the profile)
- The slot segments can be broken out in order to fix surface elements in the slot







- Important note: the load carrying capacity of the profile connection is reduced when using radial compensation!



Anti-torsion element

- Provides torsion resistance for profile connections with central bolts or quick connectors
- Subsequent installation in the connection possible

## Ordering codes

	Groove	P	D		ESD	No.
			mm			
Quick connector 90° steel, galvanized N8	8	8 / 8	11	10		3842535465
Quick connector 90° steel, galvanized N10	10	10 / 10	17	10		3842535466
Quick connector 90° steel, stainless N8	8	8 / 8	11	10		3842548937
Quick connector 90° steel, stainless N10	10	10 / 10	17	10		3842548938
Quick connector 90°, connector sleeve D = 9.8	10	10 / 10	9.8	10		3842541410
Cover cap, quick connector D11			11	100		3842538563
Cap, quick connector D17			17	100		3842538564
Cover cap, quick connector D11			11	100		3842551040
Cap, quick connector D17			17	100		3842551042