

## FEATURES

- **USB A to USB A cable**
- **Male-to-female connectors**
- **One metre long**
- **Outer cable diameter of 4.7 mm**
- **Grey PVC sheath for insulation and protection**
- **Supports high-speed transfers via USB 2.0**
- **EU REACH compliant (EC) No 1907/2006 so minimizes environmental impact**
- **CE-certified to meet EU safety, health and environmental protection requirements**

## RS PRO Male USB A to Female USB A USB Cable, USB 2.0, 1m, USB 2.0

RS Stock No.: 182-8830



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

**Product Description**

This male-to-female USB A to USB A cable supports USB 2.0 technology for fast data transfers when connecting remote devices. Its male connector plugs into the female socket on your computer. The cable flex is one metre long and has an outer diameter of 4.7 mm. Its durable PVC sheath protects the copper wire conductors within from temperature changes. There's also a drain wire inside the cable for effective grounding and foil shielding to reduce electrical interference.

**General Specifications**



<b>USB Type</b>	USB 2.0
<b>Connector A</b>	Male USB A
<b>Connector A Type</b>	USB
<b>Connector A Gender</b>	Male
<b>Connector B</b>	Female USB A
<b>Connector B Type</b>	USB A
<b>Connector B Gender</b>	Female
<b>Connector Style</b>	straight
<b>Outer Sheath Material</b>	PVC
<b>Sheath Colour</b>	Grey
<b>Applications</b>	Laptop, Phones, Cameras

**Mechanical Specifications**

<b>Length</b>	1m
---------------	----

**Approvals**

<b>Standards Met</b>	RoHS, REACH, CE
----------------------	-----------------

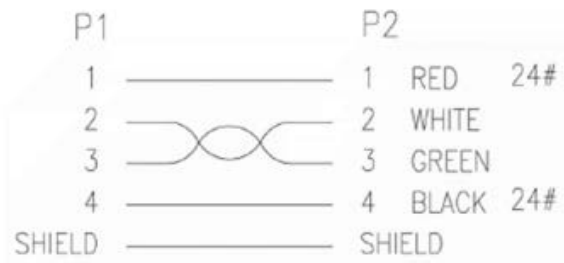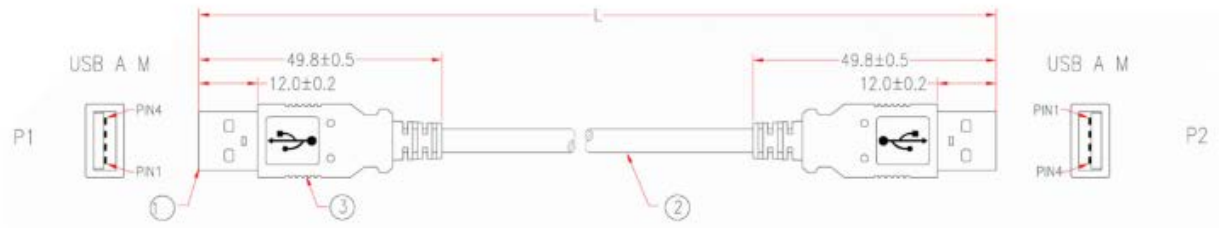

3	MOLDED PVC GREY(MZB7070)
2	USB 2.0 CABLE, UL STYLE 1 TWISTED PAIR 28AWG AND 2C 24AWG, AMA BRAID, OD 4.5mm, JACKET GREY(MZB7070), DRAWING No.EUAB2801P2402C-139
1	USB A MALE 2.0, GOLD PLATING 30µ" ON CONTACTS, WHITE INSULATOR, SHORT A PIERCE TYPE